


PRODUCT NUMBER: 1968-0-01-15-00-00-03-0


1968-0-01-15-00-00-03-0

Flat face Target contact, Press-fit in .097 mounting hole. For wire sizes up to 16AWG

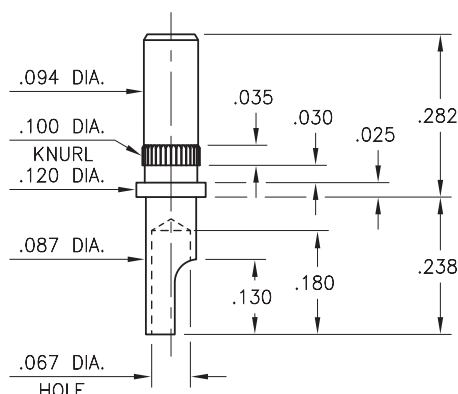

1968-1-01-15-00-00-03-0

Concave face Target contact, Press-fit in .097 mounting hole. For wire sizes up to 16AWG

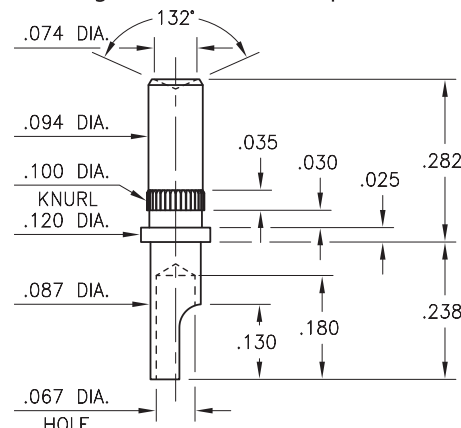

DESCRIPTION

Spring-Loaded Target Contact with Concave Face

Current Rating:

Application Specific

Operating Temperature Range:

-55/+125° C (discontinuous)

Mounting Feature:

Press-Fit into a Non-Plated Through Hole (NPTH) or Insulator

Wire Termination:

Soldercup up to 16 AWG

Mounting Hole: .097" (2,464mm)

Packaging: 01 - Packaged in Bulk

Shell Plating

10 μ" Gold over Nickel

Contact Plating

ROHS



ADDITIONAL NOTES & SPECIFICATIONS

In the interest of improved design, quality and performance, Mill-Max reserves the right to make changes in its specifications without prior notice. Specifications and tolerances are provided wherever possible. Due to the wide variety of interconnects Mill-Max offers, the specific tolerances vary from product to product. If you need information regarding the tolerance of a particular part, please contact Technical Services.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

1968-0-01-15-00-00-03-0