


# PIN RECEPTACLES

FOR .037" - .043" DIAMETER PINS

## 0331/9353

X3XX-0-15-XX-18-XX-10-0

Solder mount in .071 min. mounting hole  
Also available on 24mm wide carrier tape:  
1,000 parts per 13" reel  
Order as: X3XX-0-57-XX-18-XX-10-0

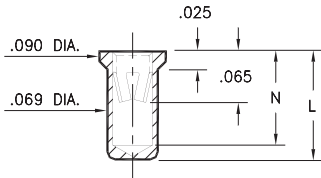


| Basic Part Number | Length L | Depth N |
|-------------------|----------|---------|
| 0331-0            | .150     | .127    |
| 9353-0            | .170     | .147    |

## 7405

7405-0-18-XX-18-XX-10-0


Press-fit in .084 mounting hole  
Accepts wire sizes up to .025" dia.

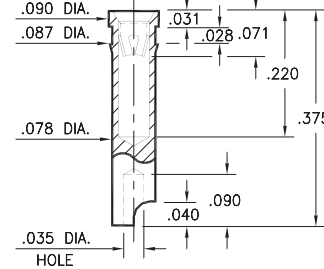

## 3450

3450-0-15-XX-18-XX-04-0


Solder mount in .043 min. mounting hole

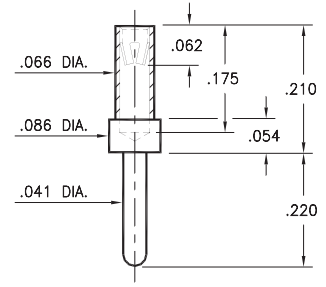

## 7406

7406-0-15-XX-18-XX-10-0


Solder mount in .071 min. mounting hole  
Also available on 16mm wide carrier tape:  
2,200 parts per 13" reel  
Order as: 7406-0-57-XX-18-XX-10-0

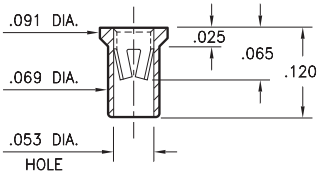

## 9354

9354-0-15-XX-18-XX-10-0


Solder mount in .071 min. mounting hole  
Also available on 12mm wide carrier tape:  
1,400 parts per 13" reel  
Order as: 9354-0-57-XX-18-XX-10-0

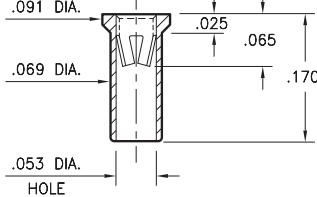

## 0319

0319-X-15-XX-18-XX-04-0


Solder mount in .042 min. mounting hole

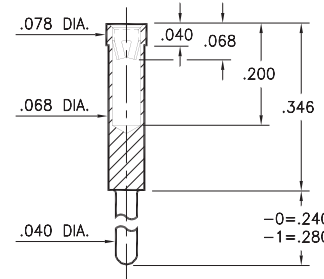

## 9357

9357-0-15-XX-18-XX-10-0


Press-fit in .078 mounting hole

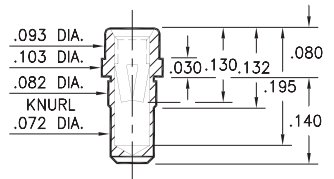

## 3520

3520-0-15-XX-18-XX-10-0


Solder mount in .070 min. mounting hole

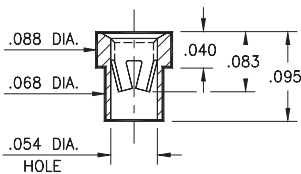

## 8331

8331-0-15-XX-18-XX-10-0


Solder mount in .071 min. mounting hole  
Also available on 16mm wide carrier tape:  
1,900 parts per 13" reel  
Order as: 8331-0-57-XX-18-XX-10-0

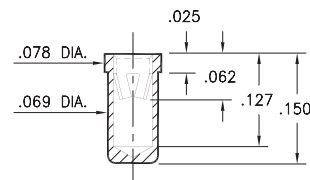

## 6628

6628-0-18-XX-18-XX-10-0


Surface mount  
Also available on 12mm wide carrier tape:  
3,700 parts per 13" reel  
Order as: 6628-0-58-XX-18-XX-10-0

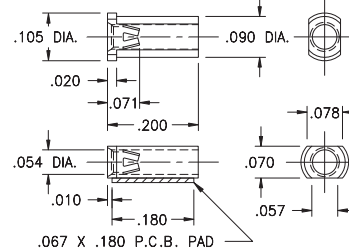

## 1313

1313-0-15-XX-18-XX-04-0

Press-fit in .056 mounting hole

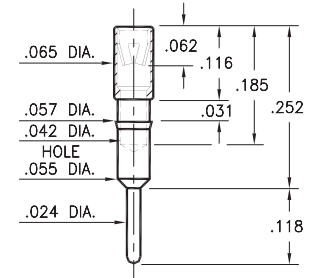

### SPECIFICATIONS:

**Shell Material:** Brass Alloy 360, 1/2 Hard

**Contact Material:** Beryllium Copper Alloy 172, HT

**Dimensions:** Inches

**Tolerances On:** Lengths:  $\pm .005$

Diameters:  $\pm .002$

Angles:  $\pm 2^\circ$



**ORDER CODE:** XXXX - X - XX - XX - 18 - XX - XX - 0

**BASIC PART #**

**SPECIFY SHELL FINISH:**

- 01 200  $\mu$ " TIN/LEAD OVER NICKEL
- ◆ 80 200  $\mu$ " TIN OVER NICKEL (RoHS)
- ◆ 15 10  $\mu$ " GOLD OVER NICKEL (RoHS)

**SPECIFY CONTACT FINISH:**

- 01 200  $\mu$ " TIN/LEAD OVER NICKEL
- ◆ 80 200  $\mu$ " TIN OVER NICKEL (RoHS)
- ◆ 27 30  $\mu$ " GOLD OVER NICKEL (RoHS)

**SELECT CONTACT:**

**#18 CONTACT (DATA ON PAGE 257)**

(For alternate contact choices, see group L on page 248)



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

9357-0-15-15-18-27-10-0