

Solder Tail Single Row

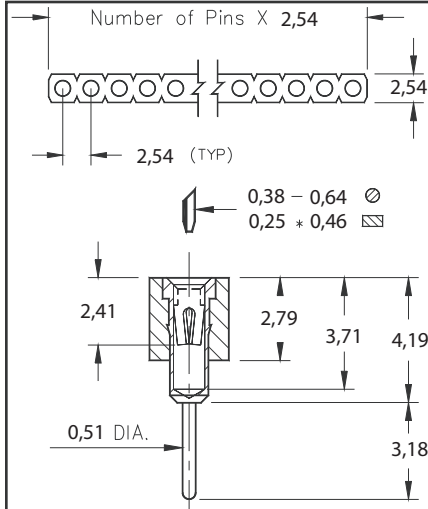


Fig. 1

- SIP sockets accept 0,38 - 0,64 diameter pins and standard IC leads.
- Various solder tails available: standard length, long for multi-layer boards, very low and ultra low profile. See Mill-Max #1001, 0134, 0501 or 1534 pins (pages 130, 131, 134) for details.
- Hi-Rel, 4-finger BeCu #12 & #30 clips rated at 3 amps. See pages 207 & 208 for details.



Ordering Information

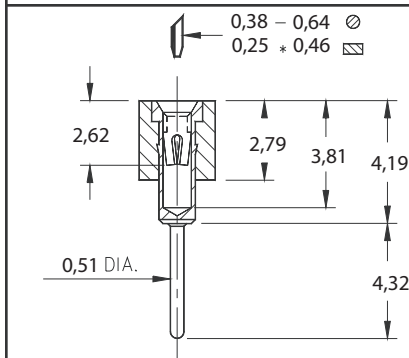


Fig. 2

Fig. 1

Series 310...001 Standard Solder Tail

310-XX-1__-41-001000

Specify # of pins → 01-64

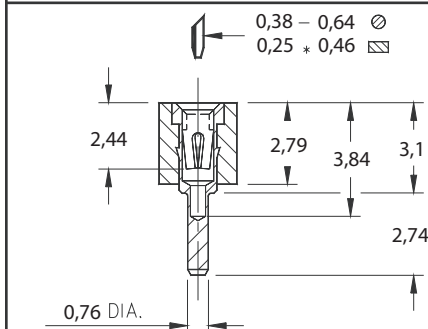


Fig. 3

Fig. 2

Series 311...001 Long Solder Tail

311-XX-1__-41-001000

Specify # of pins → 01-64

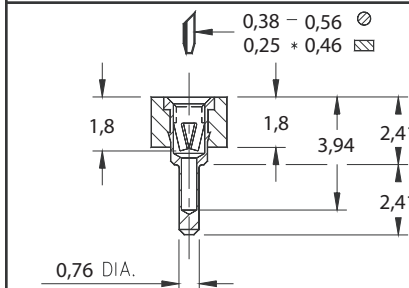


Fig. 4

Fig. 3

Series 315...001 Very Low Profile

315-XX-1__-41-001000

Specify # of pins → 01-64

Fig. 4

Series 315...003 Ultra Low Profile

315-XX-1__-41-003000

Specify # of pins → 01-64

XX=Plating Code
See Below

For RoHS compliance,
select plating code.
For the all gold option
(XX=13) also change
part number from
31X-XX-1XX-41-00X000
to
31X-13-1XX-41-00X100



SPECIFY PLATING CODE XX=	13		93	99		43	44
Sleeve (Pin)	0,25µm Au		5,08µm Sn/Pb	5,08µm Sn/Pb		5,08µm Sn	5,08µm Sn
Contact (Clip)	0,76µm Au		0,76µm Au	5,08µm Sn/Pb		0,76µm Au	5,08µm Sn

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[315-13-104-41-001100](#)