

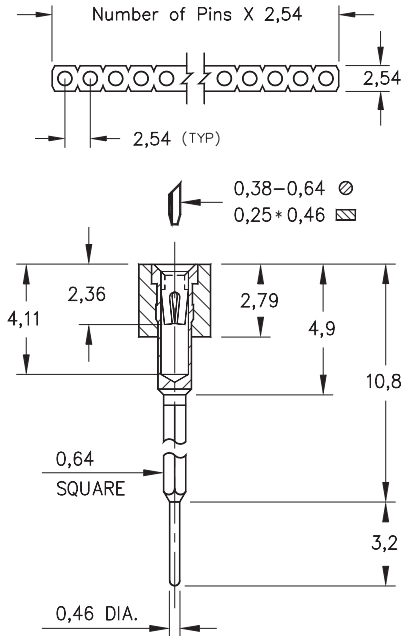


Fig. 1

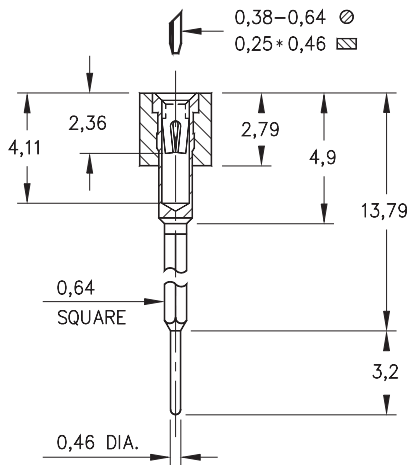


Fig. 2

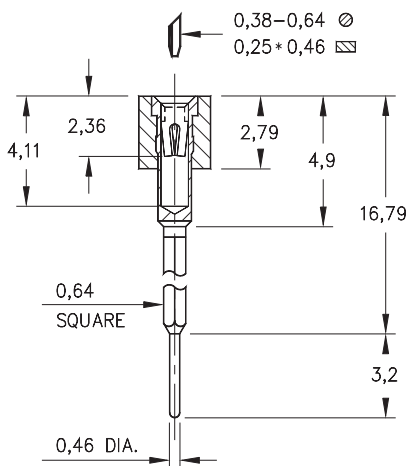


Fig. 3

- Wrapost / Solder tail combinations are available in 3 lengths using MM pin numbers:
326...001 uses pin # 2601
326...002 uses pin # 2602
326...003 uses pin # 2603
See page 167 for details.
- Hi-Rel, 4-finger BeCu #30 contact is rated at 3 amps. See page 218 for details.
- Insulators are high temp. thermoplastic.



Ordering Information

Fig. 1

Series 326...001

326-XX-1_-41-001000

Specify # of pins → 01-64

Fig. 2

Series 326...002

326-XX-1_-41-002000

Specify # of pins → 01-64

Fig. 3

Series 326...003

326-XX-1_-41-003000

Specify # of pins → 01-64

For Electrical,
Mechanical & Environmental
Data, See pg. 4

XX=Plating Code
See Below

For RoHS compliance
select ◇ plating code.

SPECIFY PLATING CODE XX=			93			43◇	
Sleeve (Pin)			5,08µm Sn/Pb			5,08µm Sn	
Contact (Clip)			0,76µm Au			0,76µm Au	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[326-43-122-41-003000](#) [326-43-128-41-003000](#) [326-43-131-41-002000](#) [326-43-140-41-003000](#) [326-43-143-41-003000](#) [326-43-154-41-003000](#) [326-43-157-41-003000](#) [326-43-160-41-003000](#) [326-43-163-41-002000](#) [326-43-108-41-003000](#) [326-43-105-41-003000](#) [326-43-119-41-003000](#) [326-43-123-41-002000](#) [326-43-136-41-002000](#) [326-43-155-41-002000](#) [326-43-138-41-002000](#) [326-43-146-41-002000](#) [326-43-146-41-003000](#) [326-43-149-41-002000](#) [326-43-149-41-003000](#) [326-43-130-41-002000](#) [326-43-156-41-003000](#) [326-43-159-41-002000](#) [326-43-127-41-002000](#) [326-43-127-41-003000](#) [326-43-139-41-003000](#) [326-43-145-41-002000](#) [326-43-153-41-003000](#) [326-43-156-41-002000](#) [326-43-161-41-003000](#) [326-43-134-41-003000](#) [326-43-151-41-003000](#) [326-43-154-41-002000](#) [326-43-162-41-002000](#) [326-43-162-41-003000](#) [326-43-126-41-003000](#) [326-43-129-41-002000](#) [326-43-129-41-003000](#) [326-43-133-41-003000](#) [326-43-141-41-003000](#) [326-43-144-41-002000](#) [326-43-144-41-003000](#) [326-43-150-41-002000](#) [326-43-152-41-003000](#) [326-43-158-41-002000](#) [326-43-125-41-003000](#) [326-43-130-41-003000](#) [326-43-140-41-002000](#) [326-43-143-41-002000](#) [326-43-148-41-002000](#) [326-43-148-41-003000](#) [326-43-157-41-002000](#) [326-43-159-41-003000](#) [326-43-110-41-003000](#) [326-43-116-41-003000](#) [326-43-131-41-003000](#) [326-43-104-41-003000](#) [326-43-107-41-003000](#) [326-43-103-41-003000](#) [326-43-124-41-002000](#) [326-43-114-41-003000](#) [326-43-102-41-003000](#) [326-43-113-41-003000](#) [326-43-126-41-002000](#) [326-43-135-41-002000](#) [326-43-135-41-003000](#) [326-43-141-41-002000](#) [326-43-152-41-002000](#) [326-43-160-41-002000](#) [326-43-111-41-003000](#) [326-43-123-41-003000](#) [326-43-133-41-002000](#) [326-43-138-41-003000](#) [326-43-147-41-002000](#) [326-43-155-41-003000](#) [326-43-158-41-003000](#) [326-43-161-41-002000](#) [326-43-163-41-003000](#) [326-43-112-41-003000](#) [326-43-115-41-003000](#) [326-43-118-41-003000](#) [326-43-122-41-002000](#) [326-43-125-41-002000](#) [326-43-128-41-002000](#) [326-43-137-41-002000](#) [326-43-137-41-003000](#) [326-43-145-41-003000](#) [326-43-151-41-002000](#) [326-43-106-41-003000](#) [326-43-109-41-003000](#) [326-43-117-41-003000](#) [326-43-121-41-002000](#) [326-43-121-41-003000](#) [326-43-124-41-003000](#) [326-43-134-41-002000](#) [326-43-136-41-003000](#) [326-43-139-41-002000](#) [326-43-142-41-002000](#) [326-43-142-41-003000](#) [326-43-147-41-003000](#)