


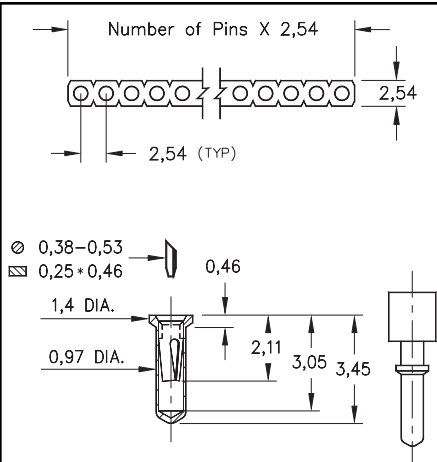


Fig. 1

- Ultra low profile receptacles sit 0,46 above the board.
- Series 714 uses MM #0552-1 and MM #0552-2 pin receptacles. See page 129 for details.
- Hi-Rel, 3-finger BeCu #11 contact is rated at 3 amps. See page 217 for details.
- Insulators are high temp. thermoplastic.

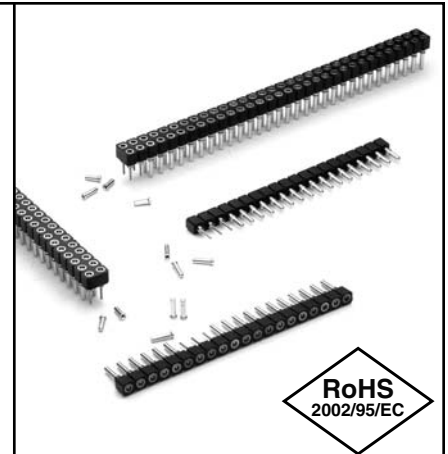

Ordering Information

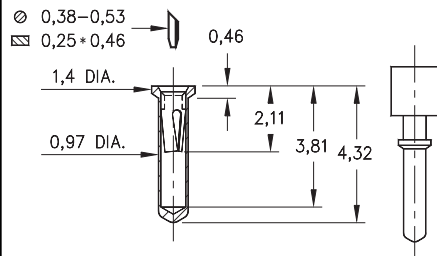


Fig. 2

Fig. 1

Single Row (0,99 min. mounting hole)

714-XX-1__-31-012000

Specify # of pins → 01-64

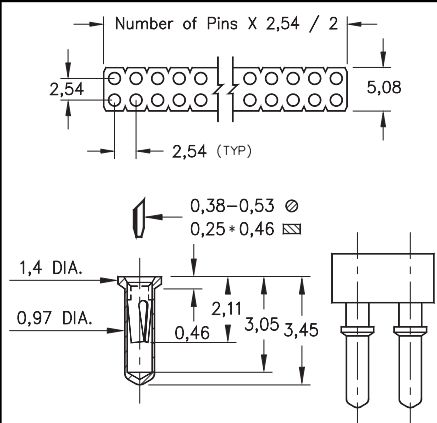


Fig. 3

Fig. 3

Single Row (0,99 min. mounting hole)

714-XX-1__-31-018000

Specify # of pins → 01-64

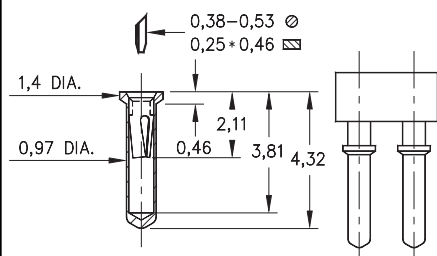


Fig. 4

Fig. 4

Double Row (0,99 min. mounting hole)

714-XX-2__-31-012000

Specify # of pins → 02-64

Double Row (0,99 min. mounting hole)

714-XX-2__-31-018000

Specify # of pins → 02-64

For Electrical,
Mechanical & Enviromental
Data, See pg. 4

XX=Plating Code
See Below

For RoHS compliance
select ◇ plating code.

SPECIFY PLATING CODE XX=			93			43◇	
Sleeve (Pin)			5,08µm Sn/Pb			5,08µm Sn	
Contact (Clip)			0,76µm Au			0,76µm Au	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[714-43-202-31-018000](#) [714-93-202-31-018000](#)