

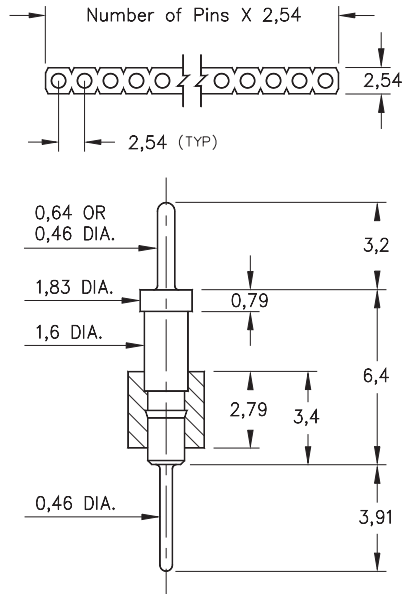


Fig. 1

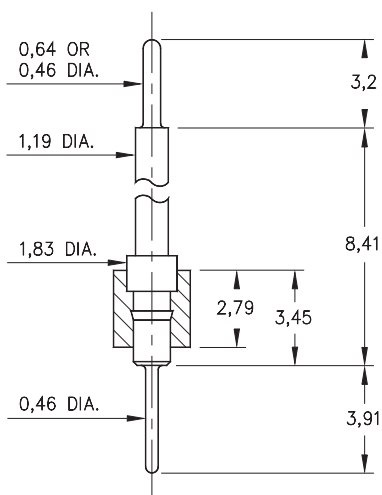


Fig. 2


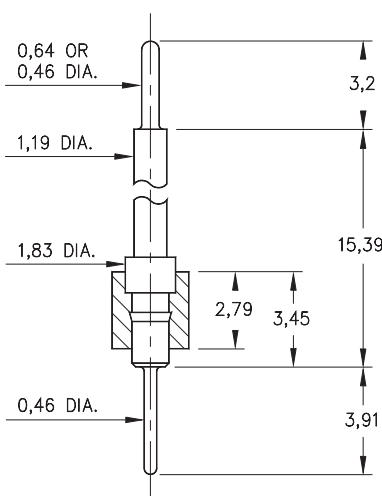


Fig. 3

- Series 351 Interconnect header strips come in three lengths with 0,46 dia. pluggable solder tails at one end and 0,64 dia. pins at the other, see series:
351...003 uses pin #5503
351...004 uses pin #5504
351...005 uses pin #5505
- 0,46 pluggable solder tails are available at both ends, please see series:
351...009 uses pin #5509
351...010 uses pin #5510
351...011 uses pin #5511
See pages 179 & 181 for details.
- Insulators are high temp. thermoplastic.

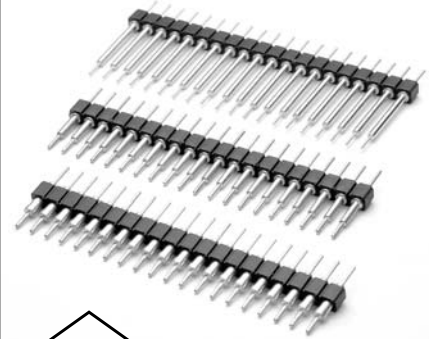

Ordering Information

Fig. 1	Series 351...003	0,46 / 0,64	Solder Tails
	351-10-1__-00-003000		
	Specify # of pins	01-64	
	Series 351...009	0,46 / 0,46	Solder Tails
Fig. 2	351-10-1__-00-009000		
	Specify # of pins	01-64	
	Series 351...004	0,46 / 0,64	Solder Tails
	351-10-1__-00-004000		
Fig. 3	Specify # of pins	01-64	
	Series 351...010	0,46 / 0,46	Solder Tails
	351-10-1__-00-010000		
	Specify # of pins	01-64	
Fig. 3	Series 351...005	0,46 / 0,64	Solder Tails
	351-10-1__-00-005000		
	Specify # of pins	01-64	
	Series 351...011	0,46 / 0,46	Solder Tails
Fig. 3	351-10-1__-00-011000		
	Specify # of pins	01-64	

For Electrical,
Mechanical & Environmental
Data, See pg. 4

For RoHS compliance
select plating code.

PLATING CODE XX=	10			
Pin Plating	0,25μ Au			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[351-10-163-00-010000](#) [351-10-140-00-010000](#) [351-10-155-00-010000](#) [351-10-162-00-010000](#) [351-10-151-00-010000](#) [351-10-158-00-010000](#) [351-10-142-00-010000](#) [351-10-146-00-010000](#) [351-10-148-00-010000](#) [351-10-147-00-010000](#) [351-10-137-00-010000](#) [351-10-141-00-010000](#) [351-10-149-00-010000](#) [351-10-138-00-010000](#) [351-10-145-00-010000](#) [351-10-159-00-010000](#) [351-10-156-00-010000](#) [351-10-139-00-010000](#) [351-10-144-00-010000](#) [351-10-153-00-010000](#) [351-10-157-00-010000](#) [351-10-160-00-010000](#) [351-10-150-00-010000](#) [351-10-154-00-010000](#) [351-10-152-00-010000](#) [351-10-161-00-010000](#) [351-10-143-00-010000](#) [351-10-104-00-010000](#) [351-10-105-00-010000](#) [351-10-110-00-010000](#) [351-10-101-00-010000](#) [351-10-106-00-010000](#) [351-10-111-00-010000](#) [351-10-121-00-010000](#) [351-10-108-00-010000](#) [351-10-115-00-010000](#) [351-10-102-00-010000](#) [351-10-119-00-010000](#) [351-10-123-00-010000](#) [351-10-117-00-010000](#) [351-10-133-00-010000](#) [351-10-130-00-010000](#) [351-10-134-00-010000](#) [351-10-113-00-010000](#) [351-10-116-00-010000](#) [351-10-109-00-010000](#) [351-10-124-00-010000](#) [351-10-128-00-010000](#) [351-10-136-00-010000](#) [351-10-122-00-010000](#) [351-10-125-00-010000](#) [351-10-129-00-010000](#) [351-10-135-00-010000](#) [351-10-131-00-010000](#) [351-10-107-00-010000](#) [351-10-112-00-010000](#) [351-10-127-00-010000](#) [351-10-114-00-010000](#) [351-10-118-00-010000](#) [351-10-126-00-010000](#)