

INTERCONNECTS

SERIES 321, 322, 323, 324 • 2,54 GRID WRAPOST • SINGLE ROW STRIPS

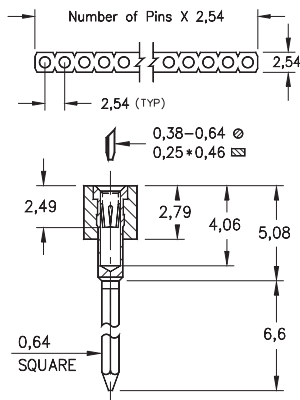


FIG. 1

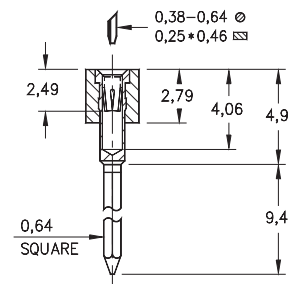


FIG. 2

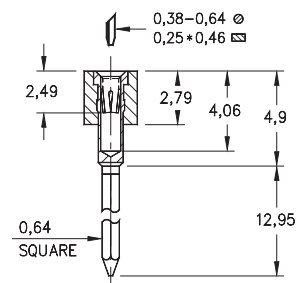


FIG. 3


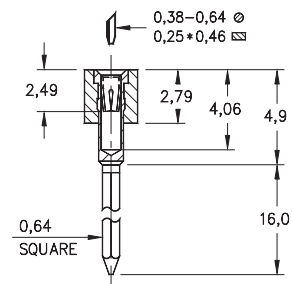


FIG. 4

- Wraposts available in 1 - 4 levels using MM pin numbers:

1-Level uses pin # 0040-1
2-Level uses pin # 0089-2
3-Level uses pin # 0088-3
4-Level uses pin # 0086-4
See page 198 for details

- Hi-Rel, 4-finger BeCu #30 contact is rated at 3 amps. See page 253 for details
- Insulators are high temperature thermoplastic, suitable for all soldering operations

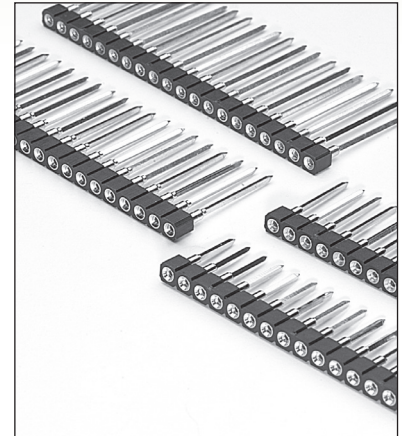

ORDERING INFORMATION

FIG. 1	Series 321...001		1 Level Wrapost		
	321-13-1-41-001000 Specify number of pins 01-64				
FIG. 2	Series 322...001		2 Level Wrapost		
	322-XX-1-41-001000 Specify number of pins 01-64				
FIG. 3	Series 323...001		3 Level Wrapost		
	323-XX-1-41-001000 Specify number of pins 01-64				
FIG. 4	Series 324...002		4 Level Wrapost		
	324-XX-1-41-002000 Specify number of pins 01-64				
RoHS - 2 2011/65/EU XX=Plating Code See Below For Electrical, Mechanical & Enviromental Data, See page 264					
SPECIFY PLATING CODE XX=					
11					
13					
91					
93					
41					
43					
Sleeve (Pin)		0,25µm Au			
Contact (Clip)		0,25µm Au			
		0,76µm Au			
		0,25µm Au			
		0,76µm Au			
		0,25µm Au			
		0,76µm Au			

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[321-13-163-41-001000](#) [323-13-102-41-001000](#) [323-43-141-41-001000](#) [323-43-142-41-001000](#) [323-43-143-41-001000](#)