

INTERCONNECTS

SERIES 334 • 2,54 GRID INTERCONNECT HEADERS • SINGLE ROW STRIPS

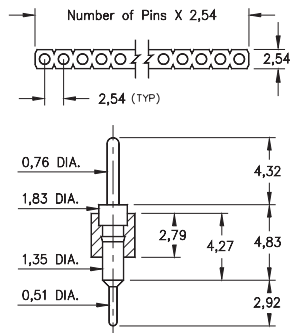


FIG. 1

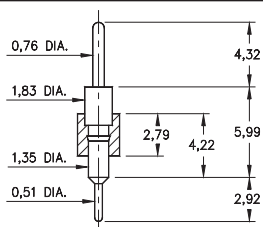


FIG. 2

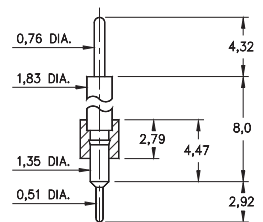


FIG. 3

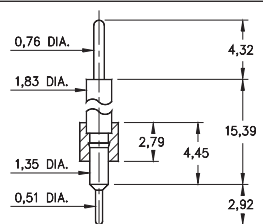


FIG. 4

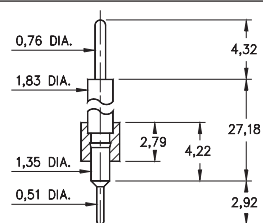


FIG. 5

- Series 334 interconnect header strips are available in 5 lengths:

334...020 uses pin #3402 (L = 4,83)
 334...010 uses pin #3401 (L = 5,99)
 334...050 uses pin #3405 (L = 8,0)
 334...000 uses pin #3400 (L = 15,39)
 334...100 uses pin #3410 (L = 27,18)
 See page 215 for details

- Strips come with 0,51 pluggable soldertails at one end and 0,76 tails at the other
- Insulators are high temperature thermoplastic, suitable for all soldering operations



ORDERING INFORMATION

FIG. 1	Series 334...020	0,51 / 0,76 Dia. Solder Tails		
	334-XX-1	-00-020000	Specify number of pins	01-64
FIG. 2	Series 334...010	0,51 / 0,76 Dia. Solder Tails		
	334-XX-1	-00-010000	Specify number of pins	01-64
FIG. 3	Series 334...050	0,51 / 0,76 Dia. Solder Tails		
	334-XX-1	-00-050000	Specify number of pins	01-64
FIG. 4	Series 334...000	0,51 / 0,76 Dia. Solder Tails		
	334-XX-1	-00-000000	Specify number of pins	01-64
FIG. 5	Series 334...100	0,51 / 0,76 Dia. Solder Tails		
	334-XX-1	-00-100000	Specify number of pins	01-64
RoHS - 2 2011/65/EU XX=Plating Code See Below For Electrical, Mechanical & Enviromental Data, See page 264				
SPECIFY PLATING CODE XX=		10 ◆	90	40 ◆
Pin Plating		0,25µm Au	5,08µm Sn/Pb	5,08µm Sn

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[334-40-116-00-100000](#) [334-40-118-00-020000](#) [334-10-158-00-000000](#) [334-10-161-00-010000](#) [334-10-161-00-020000](#) [334-10-163-00-000000](#) [334-40-103-00-010000](#) [334-40-106-00-050000](#) [334-40-108-00-050000](#) [334-40-110-00-000000](#) [334-40-110-00-010000](#) [334-40-115-00-000000](#) [334-40-118-00-050000](#) [334-10-119-00-010000](#) [334-10-121-00-100000](#) [334-10-126-00-100000](#) [334-10-130-00-010000](#) [334-10-130-00-020000](#) [334-10-131-00-100000](#) [334-10-134-00-100000](#) [334-10-137-00-100000](#) [334-10-139-00-100000](#) [334-10-118-00-050000](#) [334-10-121-00-000000](#) [334-10-124-00-020000](#) [334-10-124-00-050000](#) [334-10-129-00-020000](#) [334-10-129-00-050000](#) [334-10-133-00-050000](#) [334-10-137-00-000000](#) [334-10-138-00-050000](#) [334-10-138-00-100000](#) [334-10-139-00-000000](#) [334-10-140-00-020000](#) [334-90-115-00-020000](#) [334-90-117-00-010000](#) [334-90-119-00-000000](#) [334-10-152-00-010000](#) [334-10-154-00-000000](#) [334-10-159-00-000000](#) [334-10-162-00-000000](#) [334-40-102-00-020000](#) [334-40-105-00-100000](#) [334-40-107-00-020000](#) [334-40-109-00-010000](#) [334-40-109-00-020000](#) [334-40-110-00-100000](#) [334-40-111-00-000000](#) [334-40-114-00-010000](#) [334-40-115-00-100000](#) [334-40-117-00-020000](#) [334-10-141-00-020000](#) [334-10-143-00-000000](#) [334-10-146-00-010000](#) [334-10-147-00-100000](#) [334-10-148-00-010000](#) [334-10-149-00-050000](#) [334-10-153-00-000000](#) [334-10-153-00-010000](#) [334-10-154-00-050000](#) [334-10-154-00-100000](#) [334-10-145-00-050000](#) [334-10-147-00-000000](#) [334-10-150-00-050000](#) [334-10-157-00-000000](#) [334-10-157-00-010000](#) [334-90-121-00-010000](#) [334-40-156-00-050000](#) [334-40-156-00-100000](#) [334-90-102-00-010000](#) [334-90-103-00-050000](#) [334-90-105-00-020000](#) [334-90-108-00-100000](#) [334-90-112-00-010000](#) [334-90-114-00-000000](#) [334-10-155-00-050000](#) [334-10-157-00-020000](#) [334-10-158-00-100000](#) [334-10-160-00-050000](#) [334-10-162-00-010000](#) [334-10-162-00-020000](#) [334-10-163-00-100000](#) [334-40-101-00-000000](#) [334-40-107-00-050000](#) [334-40-112-00-020000](#) [334-40-163-00-010000](#) [334-90-101-00-050000](#) [334-90-101-00-100000](#) [334-90-103-00-010000](#) [334-90-105-00-000000](#) [334-90-106-00-050000](#) [334-90-113-00-020000](#) [334-90-115-00-000000](#) [334-90-116-00-100000](#) [334-90-118-00-050000](#) [334-10-142-00-050000](#) [334-10-144-00-010000](#) [334-10-145-00-100000](#) [334-10-156-00-000000](#) [334-10-157-00-100000](#)