



DUAL-IN-LINE SOCKETS

SERIES 605, 614 • CARRIER TYPE, LOW PROFILE • OPEN FRAME

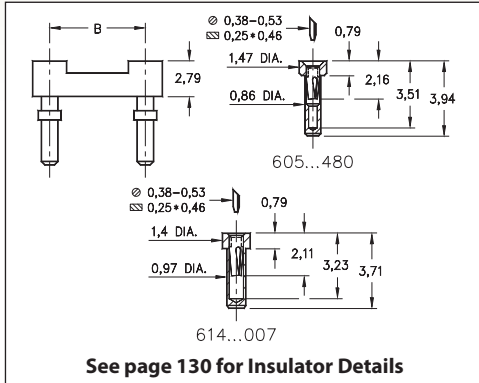

- Low profile receptacles sit only 0,79 high above the board
- Removable plastic carriers can be returned for reloading
- Hi-Rel, 3-finger BeCu #11 contact is rated at 3 amps. See page 251 for details
- Series 605 and 614 use MM #1407 & #0548 pins. See page 157 for details
- Insulators are high temperature thermoplastic, suitable for all soldering operations
- For Electrical, Mechanical and Environmental Data, see page 264 for details

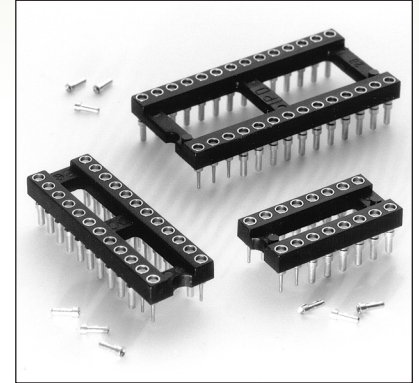

Total number of pins				Quantity per tube	ORDERING INFORMATION					
	A	B	C		Length = 3,71 (0,99 Min. Mounting Hole)	Length = 3,94 (0,89 Min. Mounting Hole)				
10	12,6	5,08	7,6	40	614-XX-210-31-007000	605-XX-210-11-480000				
4	5,0	7,62	10,1	102	614-XX-304-31-007000	605-XX-304-11-480000				
6	7,6	7,62	10,1	68	614-XX-306-31-007000	605-XX-306-11-480000				
8	10,1	7,62	10,1	50	614-XX-308-31-007000	605-XX-308-11-480000				
10	12,6	7,62	10,1	40	614-XX-310-31-007000	605-XX-310-11-480000				
14	17,7	7,62	10,1	28	614-XX-314-31-007000	605-XX-314-11-480000				
16	20,3	7,62	10,1	25	614-XX-316-31-007000	605-XX-316-11-480000				
18	22,8	7,62	10,1	22	614-XX-318-31-007000	605-XX-318-11-480000				
20	25,3	7,62	10,1	20	614-XX-320-31-007000	605-XX-320-11-480000				
22	27,8	7,62	10,1	18	614-XX-322-31-007000	605-XX-322-11-480000				
24	30,4	7,62	10,1	16	614-XX-324-31-007000	605-XX-324-11-480000				
28	35,5	7,62	10,1	14	614-XX-328-31-007000	605-XX-328-11-480000				
20	25,4	10,16	12,7	20	614-XX-420-31-007000	605-XX-420-11-480000				
22	27,8	10,16	12,7	18	614-XX-422-31-007000	605-XX-422-11-480000				
24	30,4	10,16	12,7	16	614-XX-424-31-007000	605-XX-424-11-480000				
28	35,5	10,16	12,7	14	614-XX-428-31-007000	605-XX-428-11-480000				
32	40,6	10,16	12,7	12	614-XX-432-31-007000	605-XX-432-11-480000				
24	30,4	15,24	17,7	16	614-XX-624-31-007000	605-XX-624-11-480000				
28	35,5	15,24	17,7	14	614-XX-628-31-007000	605-XX-628-11-480000				
32	40,6	15,24	17,7	12	614-XX-632-31-007000	605-XX-632-11-480000				
36	45,7	15,24	17,7	11	614-XX-636-31-007000	605-XX-636-11-480000				
40	50,8	15,24	17,7	10	614-XX-640-31-007000	605-XX-640-11-480000				
42	53,3	15,24	17,7	9	614-XX-642-31-007000	605-XX-642-11-480000				
48	60,9	15,24	17,7	8	614-XX-648-31-007000	605-XX-648-11-480000				
50	63,5	15,24	17,7	8	614-XX-650-31-007000	605-XX-650-11-480000				
52	66,0	15,24	17,7	7	614-XX-652-31-007000	605-XX-652-11-480000				
50	63,5	22,86	25,3	8	614-XX-950-31-007000	605-XX-950-11-480000				
52	66,0	22,86	25,3	7	614-XX-952-31-007000	605-XX-952-11-480000				
64	81,2	22,86	25,3	6	614-XX-964-31-007000	605-XX-964-11-480000				
SPECIFY PLATING CODE XX =					91	93	41	43		
Sleeve (Pin)					5,08µm Sn/Pb	5,08µm Sn/Pb	5,08µm Sn	5,08µm Sn		
Contact (Clip)					0,25µm Au	0,76µm Au	0,25µm Au	0,76µm Au		

RoHS-2
2011/65/EU

XX=Plating Code
See Below



Mill-Max Mfg. Corp. • 190 Pine Hollow Road, P.O. Box 300, Oyster Bay, NY 11771 • 516-922-6000 • Fax: 516-922-9253 • www.mill-max.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mill-Max:

[605-41-324-11-480000](#) [605-41-210-11-480000](#) [605-41-310-11-480000](#) [605-41-314-11-480000](#) [605-41-304-11-480000](#) [605-41-318-11-480000](#) [605-41-306-11-480000](#) [605-41-328-11-480000](#) [605-41-320-11-480000](#) [605-41-322-11-480000](#) [614-41-314-31-007000](#) [605-41-428-11-480000](#) [605-41-642-11-480000](#) [605-91-328-11-480000](#) [605-91-628-11-480000](#) [605-91-632-11-480000](#) [605-41-624-11-480000](#) [605-91-310-11-480000](#) [605-91-314-11-480000](#) [605-91-420-11-480000](#) [605-91-422-11-480000](#) [605-41-422-11-480000](#) [605-91-320-11-480000](#) [605-91-432-11-480000](#) [605-91-624-11-480000](#) [605-91-950-11-480000](#) [605-91-650-11-480000](#) [605-41-420-11-480000](#) [605-41-636-11-480000](#) [605-91-322-11-480000](#) [605-41-432-11-480000](#) [605-41-650-11-480000](#) [605-41-652-11-480000](#) [605-41-950-11-480000](#) [605-91-642-11-480000](#) [605-41-648-11-480000](#) [605-91-306-11-480000](#) [605-91-324-11-480000](#) [605-91-636-11-480000](#) [605-91-952-11-480000](#) [605-91-964-11-480000](#) [614-41-328-31-007000](#) [614-41-210-31-007000](#) [614-41-306-31-007000](#) [614-41-318-31-007000](#) [614-41-420-31-007000](#) [614-41-320-31-007000](#) [614-41-322-31-007000](#) [614-41-310-31-007000](#) [614-41-324-31-007000](#) [605-41-424-11-480000](#) [614-41-304-31-007000](#) [605-41-952-11-480000](#) [605-91-424-11-480000](#) [605-91-210-11-480000](#) [605-91-304-11-480000](#) [605-91-652-11-480000](#) [605-41-964-11-480000](#) [605-91-428-11-480000](#) [605-41-628-11-480000](#) [605-41-632-11-480000](#) [605-91-318-11-480000](#) [605-91-648-11-480000](#) [614-91-632-31-007000](#) [614-91-650-31-007000](#) [614-41-624-31-007000](#) [614-41-952-31-007000](#) [614-41-424-31-007000](#) [614-41-632-31-007000](#) [614-91-320-31-007000](#) [614-91-328-31-007000](#) [614-91-432-31-007000](#) [614-91-648-31-007000](#) [614-91-964-31-007000](#) [614-91-310-31-007000](#) [614-91-428-31-007000](#) [614-91-636-31-007000](#) [614-41-432-31-007000](#) [614-41-628-31-007000](#) [614-41-964-31-007000](#) [614-91-324-31-007000](#) [614-41-650-31-007000](#) [614-91-304-31-007000](#) [614-41-422-31-007000](#) [614-41-648-31-007000](#) [614-41-950-31-007000](#) [614-91-210-31-007000](#) [614-91-314-31-007000](#) [614-91-424-31-007000](#) [614-41-428-31-007000](#) [614-41-636-31-007000](#) [614-41-652-31-007000](#) [614-91-950-31-007000](#) [614-91-318-31-007000](#) [614-91-420-31-007000](#) [614-91-624-31-007000](#) [614-91-642-31-007000](#) [614-91-952-31-007000](#) [614-91-306-31-007000](#) [614-41-642-31-007000](#)