


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0003092021](#)
Status: **Active**
Overview: Standard .093" Pin and Socket Connectors
Description: 2.36mm Diameter Standard .093" Pin and Socket Plug Housing, 2 Circuits, with Standard Mounting Ears, Natural

Documents:

| | |
|--|---|
| Drawing (PDF) | Product Specification PS-42477-001 (PDF) |
| 3D Model | Product Specification PS-43660-9999-001 (PDF) |
| 3D Model (PDF) | Packaging Specification PK-1545-001-001 (PDF) |
| Product Specification PS-02-09 (PDF) | RoHS Certificate of Compliance (PDF) |

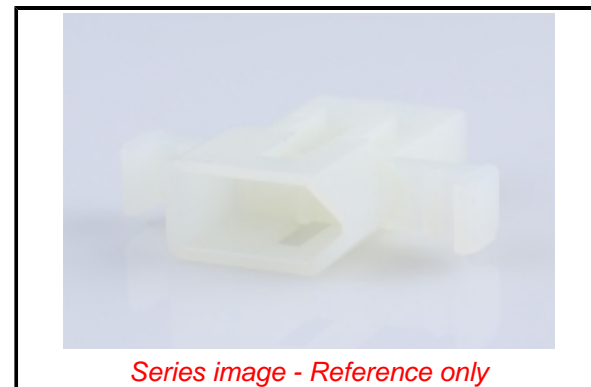

Series image - Reference only

Agency Certification

| | |
|-----|---------|
| CSA | LR19980 |
| UL | E29179 |

General

| | |
|----------------|---|
| Product Family | Crimp Housings |
| Series | 1545 |
| Application | Power, Wire-to-Wire |
| Comments | Polarized to Mating Part, 17.0A max. can be achieved when housing is used with 42477 or 42478 terminals |
| Overview | Standard .093" Pin and Socket Connectors |
| Product Name | Standard .093" |
| UPC | 800753614802 |

Physical

| | |
|-------------------------------|----------------|
| Breakaway | No |
| Circuits (maximum) | 2 |
| Circuits Detail | 1x2 |
| Color - Resin | Natural |
| Flammability | 94V-2 |
| Gender | Plug |
| Glow-Wire Capable | No |
| Keying to Mating Part | None |
| Lock to Mating Part | Yes |
| Material - Resin | Nylon |
| Net Weight | 1.811/g |
| Number of Rows | 1 |
| Packaging Type | Bag |
| Panel Mount | Yes |
| Pitch - Mating Interface | 6.30mm |
| Pitch - Termination Interface | 6.30mm |
| Stackable | No |
| Temperature Range - Operating | -40° to +105°C |

Electrical

| | |
|-------------------------------|-------|
| Current - Maximum per Contact | 14.0A |
|-------------------------------|-------|

Material Info

| | |
|--------------------|--------|
| Engineering Number | 1545-P |
|--------------------|--------|

Reference - Drawing Numbers

| | |
|-------------------------|---|
| Packaging Specification | PK-1545-001-001 |
| Product Specification | PS-02-09, PS-42477-001, PS-43660-9999-001 |
| Sales Drawing | SD-1545-X |

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2020)4578-DC (25 June 2020)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[1545 Series](#)

Mates With

[03091022](#) , [03091161](#)

Use With

[1189 Crimp Terminals](#), [1190 Crimp Terminals](#), [1376 Male PC Tail Terminals](#), [1377 Female PC Tail Terminals](#), [1380 Male Crimp Terminals](#), [1381 Female Crimp Terminals](#), [1433 Crimp Terminals](#), [1434 Male Crimp Terminals](#), [1973 Male](#)

This document was generated on 09/21/2020

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[03-09-2021](#)