

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0003122022
Status: Active
Description: 3.18mm Diameter, HCS125, Pin and Socket Plug Housing, 2 Circuits, Single Row, with and without Panel Mount Ears

Documents:
[3D Model](#) [3D Model \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR19980
UL E29179


General
Product Family Crimp Housings
Series 4306
Application Power, Wire-to-Wire
Product Name HCS-125
UPC 800754232715

Physical
Circuits (maximum) 2
Color - Resin Natural
Flammability 94V-2
Gender Plug
Glow-Wire Capable No
Material - Resin Nylon
Net Weight 1.790/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 7.11mm
Stackable No
Temperature Range - Operating -40° to +105°C

Electrical
Current - Maximum per Contact 20.0A

Material Info
Engineering Number 4306P1

Reference - Drawing Numbers
Sales Drawing 43060000-SD-000

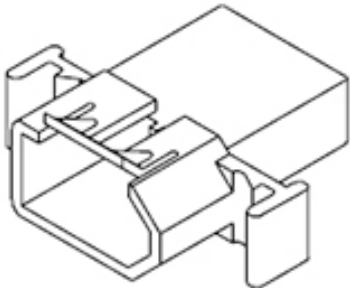

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
ECHA_01_2020 (16
January 2020
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[4306 Series](#)

Mates With
[4306](#)

Use With
[8947](#) , [1900](#) male crimp terminals, [1901](#) ,
[2046](#) , [2047](#) , [42546](#) , [42547](#) , [42554](#) , [42555](#)
 , [8946](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[03-12-2022](#)