

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0008500023

Status:


Active

Overview:

KK Interconnect Solutions

Description:

KK 396 Crimp Terminal 8818, 18-22 AWG, Bag, Brass Tin (Sn)

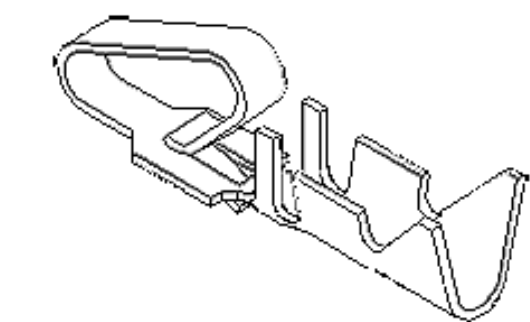

Series image - Reference only

Documents:

Drawing (PDF)

Product Specification PS-08-50-001 (PDF)

Packaging Specification PK-2759-001-001 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Terminals
Series	8818
Application	Power, Wire-to-Board
Crimp Quality Equipment	Yes
Overview	KK Interconnect Solutions
Packaging Alternative	08500008 (Reel)
Product Name	KK 396
UPC	800754233217
Physical	
Gender	Female
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.180/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	2.41mm max.
Wire Size AWG	18, 20, 22
Wire Size mm²	N/A

Solder Process Data	
Lead-freeProcess Capability	N/A

Material Info	
Engineering Number	8818-(P909)L

Reference - Drawing Numbers	
Packaging Specification	PK-2759-001-001
Product Specification	PS-08-50-001
Sales Drawing	SD-8818-001

EU ELV
Not Relevant

EU RoHS Compliant	China RoHS
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
8818 Series

Application Tooling | [FAQ](#)
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Hand Crimp Tool for 3.96mm Pitch KK Crimp Terminals, 18-22 AWG	638280300

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

08-50-0023