

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0011030016](#)
Status: **Active**
Overview: [Application Tooling](#)
Description: Extraction Tool for Flat Blade, 3.96mm KK, 2.00mm, 3.96mm EdgeMate, and Ultra-Fit Terminals

Documents:
[RoHS Certificate of Compliance \(PDF\)](#)

General


Product Family	Application Tooling
Series	207121
Comments	See Tooling Specification (PDF) Above
Function	Extraction
Geographic Area	Global
Level of Automation	Manual
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	Flat Blade, KK, KK 396, MarKK, Mini-Lock, Trifurcon, Ultra-Fit
Tool Type	Extraction Hand Tool
UPC	800753619951
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info

Engineering Number: HTA2174

Reference - Drawing Numbers

Application Tooling Documents
 ATS-011030016-001, TM-638000029-001, TM-638000029CN-001, TM-638000029DE-001, TM-638000029FR-001, TM-638000029IT-001, TM-638000029JP-001, TM-638000029KR-001, TM-638000029MY-001, TM-638000029PL-001, TM-638000029RU-001, TM-638000029SK-001, TM-638000029SP-001, TM-638000029TH-001, TM-638000029TW-001, TM-638000029VN-001

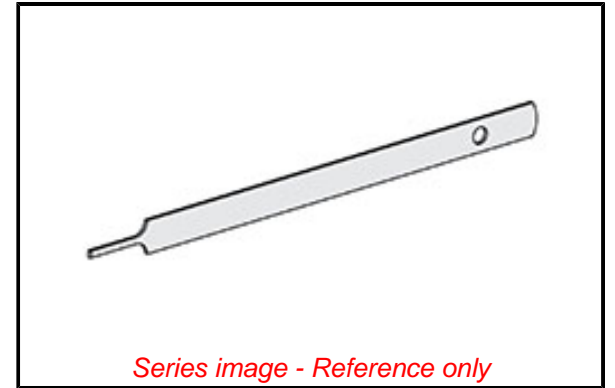

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

[207121 Series](#)

Application Tooling | **FAQ**
Description | **Product #**

Flat Blade Crimp Terminal, Series 1508, Female, With Tin (Sn) Plated Brass Contact, 14-18 AWG (or 18 AWG Double Crimp), Reel Packaged	5060117
KK 396 Crimp Terminal 2478, 18-24 AWG, Reel, Brass Tin (Sn)	8500105
KK 396 Crimp Terminal 2478, 18-24 AWG, Bag, Brass Tin (Sn)	8500106
KK 396 Crimp Terminal 2578, 22-26 AWG, Reel, Brass, 2.540µm Tin (Sn)	8500107
KK 396 Crimp Terminal 2578, 22-26 AWG, Reel, Brass, 2.540µm Tin (Sn)	8500108

AWG, Bag, Brass, 2.540µm Tin (Sn) KK 396 Crimp	<u>8500133</u>
Terminal 2578, 22-26 AWG, Reel, Phosphor Bronze, 2.540µm Tin (Sn) KK 396 Crimp	<u>8500134</u>
Terminal 2578, 22-26 AWG, Bag, Phosphor Bronze, 2.540µm Tin(Sn) KK Trifurcon Crimp	<u>8500189</u>
Terminal 6838, 18-20 AWG, Bag, Brass Tin (Sn) KK 396 Crimp	<u>8520071</u>
Terminal 2478, 18-24 AWG, Reel, Phosphor Bronze, Tin (Sn) KK 396 Crimp	<u>8520072</u>
Terminal 2478, 18-24 AWG, Bag, Phosphor Bronze, Tin (Sn) KK Trifurcon Crimp	<u>8520112</u>
Terminal 6838, 18-20 AWG, Reel, Phosphor Bronze Tin(Sn) KK Trifurcon Crimp	<u>8520113</u>
Terminal 6838, 18-20 AWG, Bag, Phosphor Bronze Tin (Sn) KK Trifurcon Crimp	<u>8520124</u>
Terminal 7258, 22-26 AWG, Reel, Phosphor Bronze Tin(Sn) KK Trifurcon Crimp	<u>8520125</u>
Terminal 7258, 22-26 AWG, Bag, Phosphor Bronze Tin (Sn) KK 156 TERMINAL	<u>8530811</u>
CRIMP 18-24 AWG KK CRIMP TERM	<u>8530812</u>
UNPLT LSE PB2478999L KK 396 Crimp	<u>8550105</u>
Terminal 2578, 22-26 AWG, Reel, Brass, 0.38µm Selective Gold (Au) KK 396 Crimp	<u>8550106</u>
Terminal 2578, 22-26 AWG, Bag, Brass, 0.38µm Selective Gold(Au) KK 396 Crimp	<u>8560105</u>
Terminal 2478, 18-24 AWG, Reel, Brass,	

0.51µm Selective
Gold (Au)
KK 396 Crimp 8560106
Terminal 2478, 18-24
AWG, Bag, Brass,
0.51µm Selective
Gold (Au)
KK 396 Crimp 8560107
Terminal 2578, 22-26
AWG, Reel, Brass,
0.51µm Select Gold
(Au) over Gold Flash
KK 396 Crimp 8560108
Terminal 2578, 22-26
AWG, Bag, Brass,
0.51µm Select Gold
(Au) over Gold Flash
KK Trifurcon Crimp 8560123
Terminal 7258,
22-26 AWG, Reel,
Phosphor Bronze
Gold (Au)
KK Trifurcon Crimp 8560124
Terminal 7258,
22-26 AWG, Bag,
Phosphor Bronze
Gold(Au)
KK Trifurcon Crimp 8580111
Terminal 6438,
18-20 AWG, Bag,
Phosphor Bronze
Selective Gold (Au)
KK 396 Crimp 8580121
Terminal 2478,
18-24 AWG, Reel,
Phosphor Bronze,
0.51µm Selective
Gold (Au)
KK 396 Crimp 8580122
Terminal 2478,
18-24 AWG, Bag,
Phosphor Bronze,
0.51µm Selective
Gold (Au)
KK 396 Crimp 8580125
Terminal 2578,
22-26 AWG, Reel,
Phosphor Bronze,
0.51µm Selective
Gold (Au)
KK 396 Crimp 8580126
Terminal 2578,
22-26 AWG, Bag,
Phosphor Bronze,
0.51µm Selective
Gold (Au)
KK Trifurcon Crimp 8580187
Terminal 6438,
18-20 AWG, Reel,
Phosphor Bronze
Gold (Au)
KK Trifurcon Crimp 8580189
Terminal 6438,
18-20 AWG, Bag,

Phosphor Bronze Gold(Au) KK 396 Crimp Terminal 2478, 18-24 AWG, Reel, Phosphor Bronze, 0.38µm Selective Gold (Au)	<u>8650114</u>
KK 396 Crimp Terminal 2478, 18-24 AWG, Bag, Phosphor Bronze, 0.38µm Selective Gold (Au)	<u>8650115</u>
KK 396 Crimp Terminal 2578, 22-26 AWG, Reel, Phosphor Bronze, 0.38µm Selective Gold (Au)	<u>8650116</u>
KK 396 Crimp Terminal 2578, 22-26 AWG, Bag, Phosphor Bronze, 0.38µm Selective Gold (Au)	<u>8650117</u>
KK Trifurcon Crimp Terminal 7258, 22-26 AWG, Reel, Phosphor Bronze Selective Gold (Au)	<u>8650121</u>
KK Trifurcon Crimp Terminal 7258, 22-26 AWG, Bag, Phosphor Bronze Selective Gold (Au)	<u>8650122</u>
3.96mm Pitch EdgeMate Crimp Terminal, Phosphor Bronze, Tin (Sn), Bifurcated, 18-20 AWG, Reel	<u>1721601803</u>
3.96mm Pitch EdgeMate Crimp Terminal, Brass, Gold (Au), Bifurcated, 18-20 AWG, Reel	<u>1721601805</u>
KK 396 Crimp Terminal 2478, 18-24 AWG, Reel, Brass, 0.9µm Pre-Plated Tin (Sn)	<u>39000286</u>
KK 156 TERMINAL CRIMP 22-26 AWG	<u>40011117</u>
KK 156 TERMINAL CRIMP 18-24 AWG	<u>40011118</u>
KK CRIMP TERM UNPLATED 24781999L	<u>40011120</u>
3.96mm (.156") Pitch MarKK Crimp Terminal, 18 to 20 AWG, Pre-Tinned Plating, Reel	<u>455703000</u>

3.96mm (.156") Pitch MarKK Crimp Terminal, 18 to 20 AWG, Tin (Sn) over Nickel (Ni) Plating, Reel	<u>455703002</u>
3.96mm (.156") Pitch MarKK Crimp Terminal, 18 to 20 AWG, Tin (Sn) over Nickel (Ni) With Select Gold (Au) Plating, Reel	<u>455703004</u>
3.96mm (.156") Pitch MarKK Crimp Terminal, 18 to 20 AWG, Pre-Tinned Plating, Bag	<u>455703050</u>
3.96mm (.156") Pitch MarKK Crimp Terminal, 18 to 20 AWG, Tin (Sn) over Nickel (Ni) Plating, Bag	<u>455703052</u>
3.96mm (.156") Pitch MarKK Crimp Terminal, 18 to 20 AWG, Tin (Sn) over Nickel (Ni) With Select Gold (Au) Plating, Bag	<u>455703054</u>
2.00mm Pitch Crimp Terminal, Male, Phosphor Bronze, 0.76µm Gold (Au) Plating, Reel	<u>506398028</u>

This document was generated on 10/07/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[11-03-0016](#)