

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0015311031](#)
Status: **Active**
Description: 4.80mm Pitch Wire-to-Wire Plug Housing, 3 Circuits

Documents:

3D Model	Product Specification PS-5025-002-001 (PDF)
3D Model (PDF)	Product Specification PS-5025-003-001 (PDF)
Drawing (PDF)	Packaging Specification SPK-5025-001-001 (PDF)
Product Specification PS-5025-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR19980
UL	E29179

General

Product Family	Crimp Housings
Series	5025
Application	Power, Wire-to-Wire
Product Name	N/A
UPC	800753604544

Physical


Circuits (maximum)	3
Flammability	94V-2
Gender	Plug
Glow-Wire Capable	No
Net Weight	1551.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	4.80mm
Pitch - Termination Interface	4.80mm
Polarized to Mating Part	Yes
Ports	1
Stackable	No
Temperature Range - Operating	-40° to +105°C

Material Info

Engineering Number	5025-03P
--------------------	----------

Reference - Drawing Numbers

Packaging Specification	SPK-5025-001-001
Product Specification	PS-5025-001-001, PS-5025-002-001, PS-5025-003-001
Sales Drawing	SD-5025-03PX-001, SD-5025-03PX-002

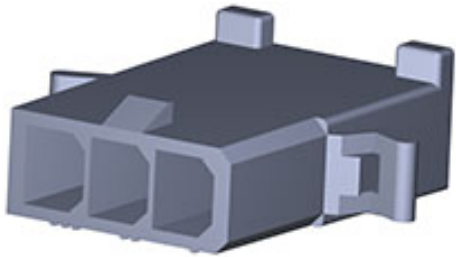

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[5025](#) Series

Mates With

[15311032](#) Receptacle

Use With

[5006](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

15-31-1031