

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0015446820

Status:


Active

Overview:

C-Grid Connector Products

Description:

2.54mm Pitch C-Grid Receptacle, Through Hole, Dual Row, High Profile, Vertical, High-Temperature, 20 Circuits

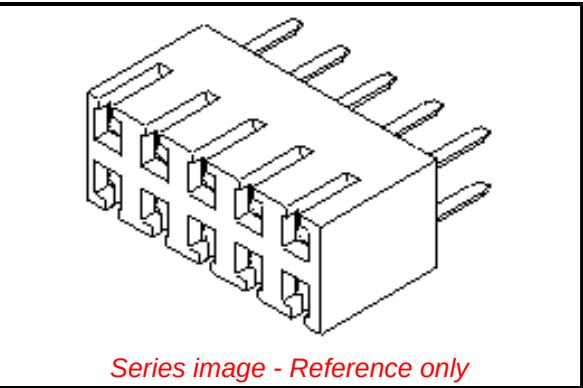

Series image - Reference only

Documents:

- [3D Model](#)
- [Drawing \(PDF\)](#)
- [3D Model \(PDF\)](#)
- [Product Specification PS-70181-001 \(PDF\)](#)
- [Application Specification 713080001-AS-000 \(PDF\)](#)
- [Packaging Specification PK-70873-0660-001 \(PDF\)](#)
- [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA

LR19980

UL

E29179

General

Product Family

PCB Receptacles

Series

71850

Application

Board-to-Board, Signal

Overview

C-Grid Connector Products

Product Name

C-Grid

UPC

800754226684

Physical

Circuits (Loaded)

20

Circuits (maximum)

20

Color - Resin

Black

Durability (mating cycles max)

25

Flammability

94V-0

Glow-Wire Capable

No

Material - Metal

Phosphor Bronze

Material - Plating Mating

Tin

Material - Plating Termination

Tin

Material - Resin

High Temperature Thermoplastic

Net Weight

1.659/g

Number of Rows

2

Orientation

Vertical

PC Tail Length

3.05mm

PCB Locator

No

PCB Retention

None

PCB Thickness - Recommended

1.57mm

Packaging Type

Tray

Pitch - Mating Interface

2.54mm

Plating min - Mating

3.810µm

Plating min - Termination

3.810µm

Polarized to PCB

No

Temperature Range - Operating

-40° to +105°C

Termination Interface: Style

Through Hole

Electrical

Current - Maximum per Contact

2.5A

Voltage - Maximum

250V

Solder Process Data

Lead-freeProcess Capability

SMC&WAVE

Process Temperature max. C

260

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

71850 Series

Mates With

C-Grid Breakaway Vertical Header [70287](#)
, [71308](#) , [70280](#)
 C-Grid Breakaway
Right-Angle Header [71764](#) , [70216](#)
 C-
Grid Vertical Headers [70246](#) , [70567](#) , [70568](#)

 C-Grid Right-Angle Headers [70247](#) ,
[70229](#) , [74162](#)

Material Info

Engineering Number 71850-0073

Reference - Drawing Numbers

Application Specification 713080001-AS-000
Packaging Specification PK-70873-0660-001
Product Specification PS-70181-001
Sales Drawing SDA-71850-0XXX-001

This document was generated on 09/13/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

15-44-6820