

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0015453220

Status:


Active

Overview:

C-Grid Connector Products

Description:

2.54mm Pitch C-Grid PCB Connector, Surface Mount, High Profile, Dual Row, Vertical, 20 Circuits

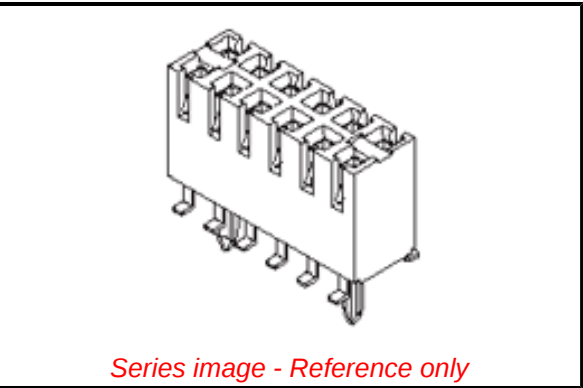

Documents:	
3D Model	Application Specification AS-71395-001-001 (PDF)
Drawing (PDF)	Packaging Specification PK-70873-0304-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-71395-001 (PDF)	

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	PCB Receptacles
Series	71395
Application	Board-to-Board, Signal
Overview	C-Grid Connector Products
Product Name	C-Grid
UPC	800754203753
Physical	
Circuits (Loaded)	20
Circuits (maximum)	20
Color - Resin	Black
Durability (mating cycles max)	25
Flammability	94V-0
Glow-Wire Capable	No
Guide to Mating Part	No
Keying to Mating Part	None
Lock to Mating Part	No
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	1.659/g
Number of Rows	2
Orientation	Vertical
PC Tail Length	1.47mm
PCB Locator	Yes
PCB Retention	None
PCB Thickness - Recommended	1.57mm
Packaging Type	Tray
Pitch - Mating Interface	2.54mm
Plating min - Mating	3.810µm
Plating min - Termination	3.810µm
Polarized to PCB	No
Surface Mount Compatible (SMC)	N/A
Temperature Range - Operating	-40° to +105°C
Termination Interface: Style	Surface Mount
Electrical	
Current - Maximum per Contact	2.5A
Grounding to PCB	No

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

71395 Series

Mates With

C-Grid Vertical Header [70246](#) , [70227](#) , [70567](#)
 C-Grid Right Angle Header [70247](#) , [74162](#)
 C-Grid Breakaway Header [70287](#) , [70280](#) , [70524](#)

Voltage - Maximum	250V
Solder Process Data	
Lead-freeProcess Capability	REFLOW
Process Temperature max. C	260
Material Info	
Engineering Number	A713951020
Reference - Drawing Numbers	
Application Specification	AS-71395-001-001
Packaging Specification	PK-70873-0304-001
Product Specification	PS-71395-001
Sales Drawing	SDA-71395-1XXX-001

This document was generated on 12/20/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

15-45-3220