

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0015910608

Status:

Active

Overview:

C-Grid Connector Products

Description:

2.54mm Pitch C-Grid Breakaway Header, Surface Mount, Dual Row, Vertical, 60 Circuits, 0.38µm Gold (Au) Selective Plating, with 8.13mm Mating Pin Length

Documents:

- 3D Model

Application Specification 713080001-AS-000 (PDF)
- 3D Model (PDF)

Packaging Specification 713080003-PK-000 (PDF)
- Drawing (PDF)

RoHS Certificate of Compliance (PDF)
- Product Specification PS-71308-001 (PDF)

Agency Certification

CSA

LR19980

UL

E29179

General

Product Family

PCB Headers

Series

71308

Application

Board-to-Board, Signal, Wire-to-Board

Overview

C-Grid Connector Products

Product Name

C-Grid

UPC

800754653008

Physical

Breakaway

Yes

Circuits (Loaded)

60

Circuits (maximum)

60

Color - Resin

Black

Durability (mating cycles max)

50

Flammability

94V-0

Glow-Wire Capable

No

Lock to Mating Part

None

Material - Metal

Phosphor Bronze

Material - Plating Mating

Gold

Material - Plating Termination

Tin

Material - Resin

High Temperature Thermoplastic

Net Weight

14.603/g

Number of Rows

2

Orientation

Vertical

PCB Locator

No

PCB Retention

None

Packaging Type

Tube

Pitch - Mating Interface

2.54mm

Plating min - Mating

0.381µm

Plating min - Termination

1.905µm

Polarized to Mating Part

No

Polarized to PCB

No

Shrouded

No

Stackable

Yes

Temperature Range - Operating

-40° to +105°C

Termination Interface: Style

Surface Mount

Electrical


Current - Maximum per Contact

3.0A

Voltage - Maximum

250V

Solder Process Data

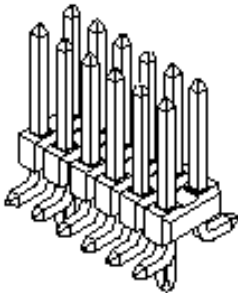

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series
71308 Series

Lead-free	Process Capability	REFLOW
	Process Temperature max. C	260
Material Info		
	Engineering Number	71308-1160
Reference - Drawing Numbers		
	Application Specification	713080001-AS-000
	Packaging Specification	713080003-PK-000
	Product Specification	PS-71308-001
	Sales Drawing	713080000-SD-000

This document was generated on 03/04/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15-91-0608](#)