

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0015913740

Status:

Active

Overview:

C-Grid Connector Products

Description:

2.54mm Pitch C-Grid Breakaway Header, Surface Mount, Dual Row, Vertical, 74 Circuits, 0.76µm Gold (Au) Selective Plating, without PCB Locator Pegs

Documents:

3D Model

3D Model (PDF)


Drawing (PDF)

Product Specification PS-71308-001 (PDF)

Application Specification 713080001-AS-000 (PDF)

Packaging Specification 713080001-PK-000 (PDF)

RoHS Certificate of Compliance (PDF)

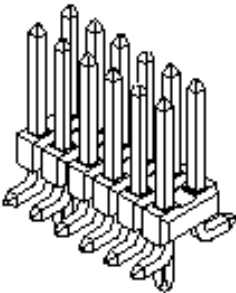

Series image - Reference only

Agency Certification		
CSA		LR19980
UL		E29179
General		
Product Family		PCB Headers
Series		71308
Application		Board-to-Board, Signal, Wire-to-Board
Overview		C-Grid Connector Products
Product Name		C-Grid
UPC		800754660235

Physical		
Breakaway		Yes
Circuits (Loaded)		74
Circuits (maximum)		74
Color - Resin		Black
Durability (mating cycles max)		50
Flammability		94V-0
Glow-Wire Capable		No
Lock to Mating Part		None
Material - Metal		Phosphor Bronze
Material - Plating Mating		Gold
Material - Plating Termination		Tin
Material - Resin		High Temperature Thermoplastic
Net Weight		4.247/g
Number of Rows		2
Orientation		Vertical
PCB Locator		No
PCB Retention		None
Packaging Type		Tube
Pitch - Mating Interface		2.54mm
Plating min - Mating		0.762µm
Plating min - Termination		1.905µm
Polarized to Mating Part		No
Polarized to PCB		No
Shrouded		No
Stackable		Yes
Temperature Range - Operating		-40° to +105°C
Termination Interface: Style		Surface Mount

Electrical		
Current - Maximum per Contact		3.0A
Voltage - Maximum		250V

Solder Process Data

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Reviewed	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series
71308 Series

Duration at Max. Process Temperature (seconds)	030
Lead-freeProcess Capability	REFLOW
Max. Cycles at Max. Process Temperature	003
Process Temperature max. C	260
Material Info	
Engineering Number	71308-0274
Reference - Drawing Numbers	
Application Specification	713080001-AS-000
Packaging Specification	713080001-PK-000
Product Specification	PS-71308-001

This document was generated on 07/30/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

15-91-3740