

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0022011032](#)
Status: **Active**
Overview: [KK Interconnect Solutions](#)
Description: 2.50mm Pitch KK Wire-to-Board Housing, Female, Friction Lock, for 2759/5159 Crimp Terminals, 3 Circuits

Documents:

3D Model	Product Specification PS-5045-003-001 (PDF)
3D Model (PDF)	Product Specification PS-5045-004-001 (PDF)
Drawing (PDF)	Product Specification PS-5051-005-001 (PDF)
Product Specification 50510000-000 (PDF)	Product Specification PS-5051-006-001 (PDF)
Product Specification 50510002-PS-000 (PDF)	Product Specification PS-5102-004-001 (PDF)
Product Specification PS-5045-001-001 (PDF)	Packaging Specification SPK-5051-001-001 (PDF)
Product Specification PS-5045-002-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

UL E29179

General

Product Family Crimp Housings
Series [5051](#)
Application Signal, Wire-to-Board
Overview [KK Interconnect Solutions](#)
Product Name KK
UPC 800753594340

Physical


Circuits (maximum) 3
Color - Resin Natural
Flammability 94V-0
Gender Receptacle
Glow-Wire Capable No
Material - Resin Nylon
Net Weight 433.800/mg
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.50mm
Stackable No
Temperature Range - Operating -40° to +105°C

Material Info

Engineering Number 5051-03

Reference - Drawing Numbers

Packaging Specification SPK-5051-001-001
Product Specification 50510000-000, 50510002-PS-000, PS-5045-001-001, PS-5045-002-001, PS-5045-003-001, PS-5045-004-001, PS-5051-005-001, PS-5051-006-001, PS-5102-004-001
Sales Drawing SD-5051-001-001

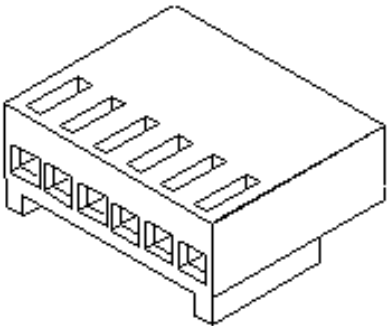

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series

[5051](#) Series

Mates With

Vertical Header [5045](#)
 Right Angle Header [5046](#)

Use With

KK 254 Crimp Terminal [2759](#)
 KK Cat Ear Crimp Terminal [5159](#)
 KK 254 Pre-Crimped Leads [797580007](#) , [797580015](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[22-01-1032](#)