

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0022153073
Status: Active
Overview: ffc_fpc_throughhole
Description: 2.54mm (.100") Right Angle, Non-ZIF, Low Profile Receptacle, 7 Circuits

Documents:

- | | |
|---|---|
| 3D Model | Product Specification PS-5229-005 (PDF) |
| Drawing (PDF) | Product Specification PS-5229-006 (PDF) |
| Product Specification PS-5229-003 (PDF) | Product Specification PS-5229-007 (PDF) |
| Product Specification PS-5229-004 (PDF) | RoHS Certificate of Compliance (PDF) |

Agency Certification

UL E29179

General

Product Family	FFC/FPC Connectors
Series	5229
Overview	ffc_fpc_throughhole
Product Name	N/A

Physical

Circuits (Loaded)	7
Contact Position	Bottom
Entry Angle	90° Angle
Flammability	94V-0
Mated Height	6.60mm (.260")
Number of Rows	1
Orientation	Right Angle
PC Tail Length	3.60mm (.142")
PCB Retention	None
Packaging Type	Tray
Pitch - Mating Interface	2.54mm (.100")
Pitch - Termination Interface	2.54mm (.100")
Polarized to PCB	No
Stackable	No
Surface Mount Compatible (SMC)	No
Temperature Range - Operating	-40°C to +105°C
Termination Interface: Style	Through Hole
Wire/Cable Type	FFC/FPC

Electrical

Current - Maximum per Contact	0.5A, 1A
Voltage - Maximum	200V

Material Info

Old Part Number 5229-07APB

Reference - Drawing Numbers

Product Specification	PS-5229-003, PS-5229-004, PS-5229-005, PS-5229-006, PS-5229-007
Sales Drawing	SD-5229-NAPB

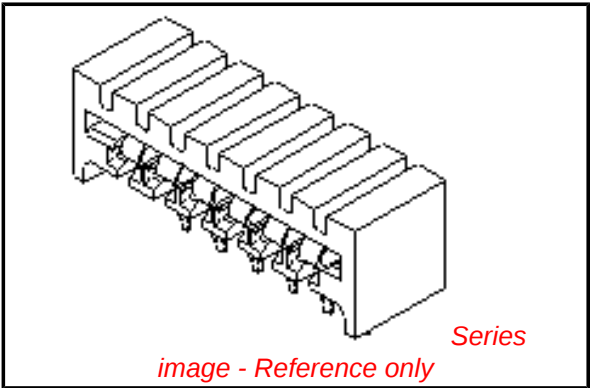


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

5229Series

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[22-15-3073](#)