

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0022552443

Status:


Active

Overview:

SL Modular Connectors

Description:

2.54mm Pitch SL Crimp Housing, Dual Row, Version C, Back Ribs, 44 Circuits, Black

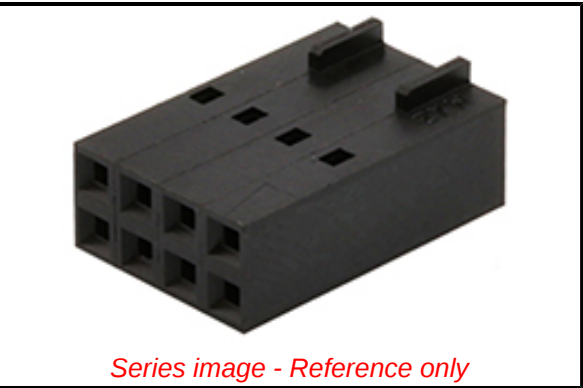

Documents:	
3D Model	Product Specification PS-70400-001 (PDF)
3D Model (PDF)	Packaging Specification PK-70450-100-001 (PDF)
Drawing (PDF)	Test Summary TS-70058-001-001 (PDF)
Product Specification PS-70058-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	70450
Application	Signal, Wire-to-Board
Comments	Version C
Overview	SL Modular Connectors
Product Name	SL
UPC	800753778702
Physical	
Breakaway	No
Circuits (maximum)	44
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Polyester
Net Weight	3.772/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	Yes
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	70450-0120
Reference - Drawing Numbers	
Packaging Specification	PK-70450-100-001
Product Specification	PS-70058-001, PS-70400-001
Sales Drawing	SD-70450-0100-0125-001
Test Summary	TS-70058-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

70450 Series

Mates With

2.54mm Pitch C-Grid Header [70229](#) , [70280](#) , [70246](#) , [70247](#)

Use With

[70058](#) , [71851](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[22-55-2443](#)