


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0022552481](#)
Status: **Active**
Overview: [SL Modular Connectors](#)
Description: 2.54mm Pitch SL Crimp Housing, Dual Row, Version A, Non-polarized, 48 Circuits, Black

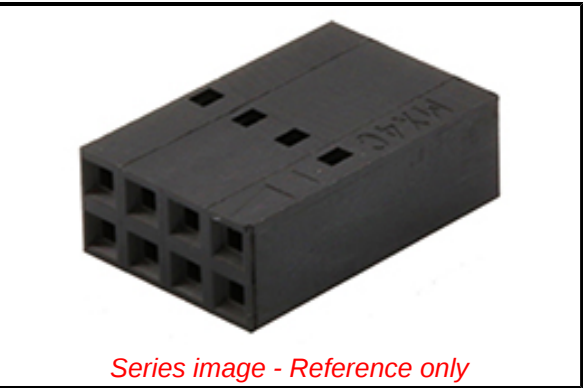

Documents:
[3D Model](#)
[3D Model \(PDF\)](#)
[Drawing \(PDF\)](#)
[Product Specification PS-70058-001 \(PDF\)](#)
[Product Specification PS-70400-001 \(PDF\)](#)
[Packaging Specification PK-70450-100-001 \(PDF\)](#)
[Test Summary TS-70058-001-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR19980
UL E29179

General
Product Family Crimp Housings
Series [70450](#)
Application Signal, Wire-to-Board
Comments Version A
Overview [SL Modular Connectors](#)
Product Name SL
UPC 800753778726

Physical
Breakaway No
Circuits (maximum) 48
Color - Resin Black
Flammability 94V-0
Gender Receptacle
Glow-Wire Capable No
Material - Resin Polyester
Net Weight 4.080/g
Number of Rows 2
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.54mm
Stackable Yes
Temperature Range - Operating -40° to +105°C

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number 70450-0023

Reference - Drawing Numbers
Packaging Specification PK-70450-100-001
Product Specification PS-70058-001, PS-70400-001
Sales Drawing SD-70450-0001-0026-001
Test Summary TS-70058-001-001

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[70450 Series](#)

Mates With
2.54mm Pitch C-Grid Header [70229](#) , [70280](#) , [70246](#) , [70247](#)

Use With
[70058](#) , [71851](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[22-55-2481](#)