

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0022566347

Status:


Active

Overview:

SL Modular Connectors

Description:

2.54mm Pitch SL Crimp Housing, Dual Row, Version F, 34 Circuits, Black

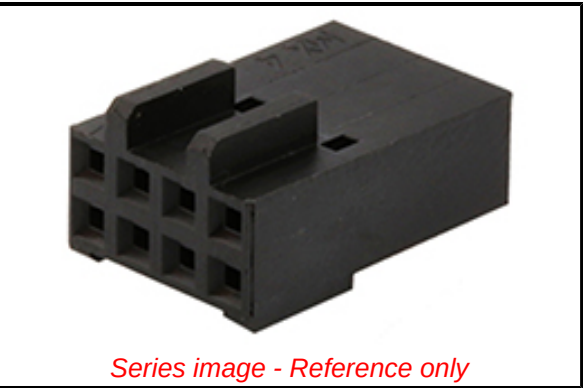

Series image - Reference only

Documents:	
3D Model	Product Specification PS-70400-001 (PDF)
Drawing (PDF)	Packaging Specification PK-70450-100-001 (PDF)
3D Model (PDF)	Test Summary TS-70058-001-001 (PDF)
Product Specification PS-70058-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR19980
UL	E29179
General	
Product Family	Crimp Housings
Series	70450
Application	Signal, Wire-to-Board
Comments	Version F
Overview	SL Modular Connectors
Product Name	SL
UPC	800754201377
Physical	
Breakaway	No
Circuits (maximum)	34
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Material - Resin	Polyester
Net Weight	2.954/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.54mm
Stackable	No
Temperature Range - Operating	-40° to +105°C
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	704500265
Reference - Drawing Numbers	
Packaging Specification	PK-70450-100-001
Product Specification	PS-70058-001, PS-70400-001
Sales Drawing	SD-70450-0250-0275-001
Test Summary	TS-70058-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
70450 Series
Mates With
2.54mm Pitch C-Grid Header 70229 , 70280 , 70246 , 70247
Use With
70058 , 71851

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[22-56-6347](#)