

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION


Part Number: [0039000282](#)
Status: **Active**
Overview: [Standard .093" Pin and Socket Connectors](#)
Description: 2.36mm Diameter, Standard .093" Pin and Socket Crimp Terminal, Series 1189, Female, with Tin (Sn) over Copper Plated Brass Contact, 14-20 AWG, Reel, with Dimple

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-1189-008 \(PDF\)](#)
[Drawing \(PDF\)](#) [Packaging Specification SPK-1189-001-001 \(PDF\)](#)
[Product Specification PS-1189-007 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Crimp Terminals
Series	1189
Application	Power
Comments	with Dimple
Crimp Quality Equipment	Yes
Overview	Standard .093" Pin and Socket Connectors
Product Name	Standard .093"
UPC	800753584822
Physical	
Gender	Female
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	339.000/mg
Packaging Type	Reel
Plating min - Mating	0.889µm
Plating min - Termination	0.889µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.60-4.10mm
Wire Size AWG	14, 16, 18, 20
Wire Size mm²	N/A

Material Info	
Engineering Number	1189T

Reference - Drawing Numbers	
Crimp Specification	CS-1189_1190
Packaging Specification	SPK-1189-001-001
Product Specification	PS-1189-007, PS-1189-008
Sales Drawing	SD-1189-002

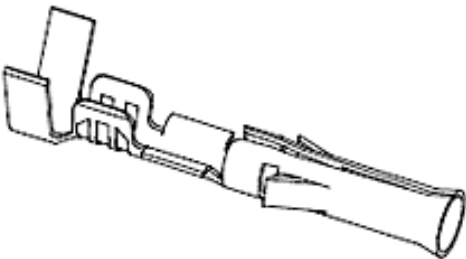

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - ECHA_01_2020 (16 January 2020 Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Contained

Search Parts in this Series
[1189 Series](#)

Use With
[3191](#) Receptacle

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Extraction Tool	11030006
Terminator Die	11402001
Extractor Tool	638240200
for .093 and HCS-125 Product Series	
Mini-Mac Applicator for Insulation OD 1.65-2.79mm, 14-20 AWG Wire	638927100

Mini-Mac Applicator <u>638927300</u> for Insulation OD 2.54-4.06mm, 14-20 AWG Wire	
Japan	
Description	Product #
Hand Extraction Tool	<u>11260029</u>
Applicator for M211A	<u>11260069</u>
Bench Press, 14-28 AWG Wire	

This document was generated on 04/01/2020

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[39-00-0282 \(Mouser Reel\)](#) [39-00-0282 \(Cut Strip\)](#)