

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0082245917](#)
Status: **Active**
Description: 2.54mm Pitch Round Conductor Flat Cable - 24 AWG (7 x 32) Stranded, Topcoat, 17 Circuits, Reel 30.48m Length

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable
Series	8997
Crimp Quality Equipment	Yes
Geographic Area	Asia
Product Name	Ribbon
UPC	800754965422

Physical

Cable Length	30.48m
Circuits (Loaded)	17
Insulation	PVC
Packaging Type	Reel
Pitch - Termination Interface	2.54mm
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	24
Wire/Cable Type	(7x32) Stranded, Topcoat

Electrical


Current - Maximum per Contact	N/A
Voltage - Maximum	300V

Material Info

Engineering Number	8997-17-100B
--------------------	--------------

Reference - Drawing Numbers

Sales Drawing	SD-8997-001
---------------	-------------

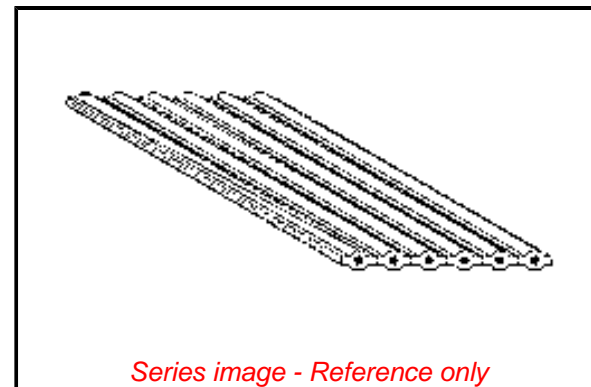

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[8997 Series](#)

Use With

[70400 C-Grid SL IDT Connector Assembly.](#)
[70475 SL IDT Connector Assembly.](#) [7720](#)
[KK IDT Double Cantilever Contact](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[82-24-5917](#)