


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0082264407](#)
Status: **Active**
Description: 2.00mm Pitch Round Conductor Flat Cable - 26 AWG (7 x 34) Stranded, Topcoat, 7 Circuits, Reel 30.48m Length

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable
Series	24462
Crimp Quality Equipment	Yes
Geographic Area	Asia
Product Name	Ribbon
UPC	800754989299
Physical	
Cable Length	30.48m
Circuits (Loaded)	7
Insulation	PVC
Net Weight	790.180/g
Packaging Type	Reel
Pitch - Termination Interface	2.00mm
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	26
Wire/Cable Type	(7x34) Stranded, Topcoat
Electrical	
Current - Maximum per Contact	N/A
Voltage - Maximum	300V
Material Info	
Engineering Number	24462-07-100B
Reference - Drawing Numbers	
Sales Drawing	SD-24462-001

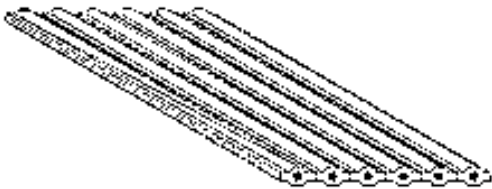

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant REACH SVHC Not Contained Per - ED/39/2015 (15 June 2015) Halogen-Free Status Not Low-Halogen Need more information on product environmental compliance? Email productcompliance@molex.com Please visit the Contact Us section for any non-product compliance questions.	China RoHS China ROHS ELV RoHS Phthalates
	Green Image Not Relevant Not Reviewed

Search Parts in this Series
[24462](#) Series

Use With
[52484](#) Wire-to-Board, IDT Receptacle
Housing

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

82-26-4407