

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0150150445](#)
Status: **Active**
Overview: Premo-Flex Flat-Flexible Cable (FFC) Jumpers
Description: 0.30mm Pitch Premo-Flex Etched Copper Polyimide Jumper, Same Side Contacts (Type A), 102.00mm Cable Length, Gold (Au) Plating, 45 Circuits

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-15015-001-001 \(PDF\)](#)

General

Product Family	Cable
Series	15015
Crimp Quality Equipment	Yes
Overview	<u>Premo-Flex Flat-Flexible Cable (FFC) Jumpers</u>
Product Name	Premo-Flex FFC Jumper
UPC	884982822580

Physical

Cable Length	102.00mm
Circuits (Loaded)	45
Material - Plating Mating	Gold
Net Weight	1.000/g
Packaging Type	Bag
Pitch - Mating Interface	0.30mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable


Electrical

Current - Maximum per Contact	0.2A
Voltage - Maximum	50V AC/DC

Material Info

Reference - Drawing Numbers

Product Specification	PS-15015-001-001
Sales Drawing	SD-15015-001

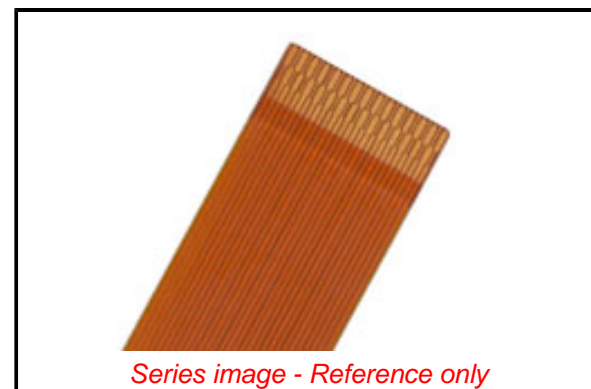

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)4578-DC (25
June 2020)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[15015 Series](#)

Mates With

Easy-On FPC Connector [5025984593](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15015-0445](#)