

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0150150645](#)  
**Status:** **Active**  
**Overview:** FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers  
**Description:** 0.30mm Pitch Premo-Flex Etched Copper Polyimide Jumper, Same Side Contacts (Type A), 152.00mm Cable Length, Gold (Au) Plating, 45 Circuits

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Datasheet (PDF)</a>
<a href="#">Product Specification PS-15015-001-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**General**

Product Family	Cable
Series	<a href="#">15015</a>
Crimp Quality Equipment	Yes
Overview	<a href="#">FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers</a>
Product Name	Premo-Flex FFC Jumper
UPC	884982822665

**Physical**

Cable Length	152.00mm
Circuits (Loaded)	45
Contact Layout Type	A (same side)
Material - Plating Mating	Gold
Net Weight	1.000/g
Packaging Type	Bag
Pitch - Mating Interface	0.30mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable


**Electrical**

Current - Maximum per Contact	0.2A
Voltage - Maximum	50V AC/DC

**Material Info**

**Reference - Drawing Numbers**

Product Specification	PS-15015-001-001
Sales Drawing	SD-15015-001-001

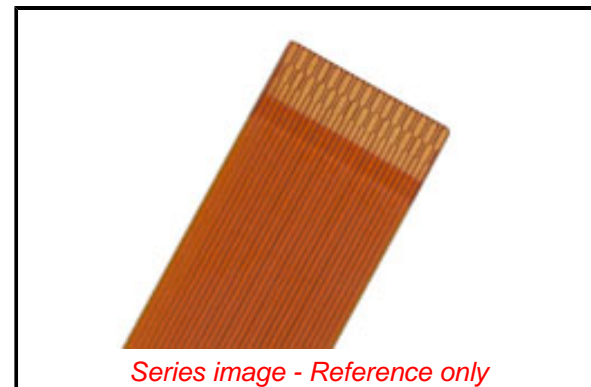

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[15015 Series](#)

**Mates With**

Easy-On FPC Connector [5025984593](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15015-0645](#)