


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0150200088
Status: Active
Overview: FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Description: 0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 203.00mm Cable Length, Gold (Au) Plating, 8 Circuits

Documents:
[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification PS-15020-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	Cable
Series	15020
Comments	Contacts on opposite sides, Type D
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
UPC	884982175501
Physical	
Cable Length	203.00mm
Circuits (Loaded)	8
Contact Layout Type	D (opposite side)
Material - Plating Mating	Gold
Net Weight	0.531/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable
Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-15020-001-001
Sales Drawing	SD-15020-001-001

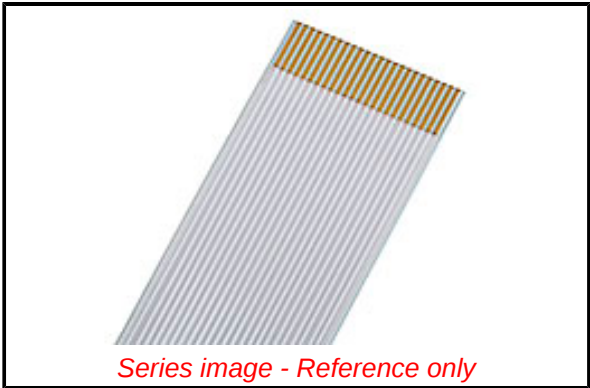

EU ELV Not Reviewed	
EU RoHS Not Reviewed REACH SVHC Not Reviewed Halogen-Free Status Not Reviewed	China RoHS
For more information, please visit Contact US	
China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series
15020 Series

Mates With
Easy-On FFC/FPC Connector:

[5034800800](#) , [5051100892](#) , [527450897](#) ,
[527460871](#) , [5019510830](#) , [5019510850](#) ,
[525590853](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

15020-0088