


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0150200097](#)
Status: **Active**
Overview: Premo-Flex Flat-Flexible Cable (FFC) Jumpers
Description: 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 51.00mm Cable Length, Gold (Au) Plating, 10 Circuits

Documents:

Drawing (PDF)	Datasheet (PDF)
Product Specification PS-15020-001-001 (PDF)	RoHS Certificate of Compliance (PDF)
Packaging Specification PK-15020-001-001 (PDF)	

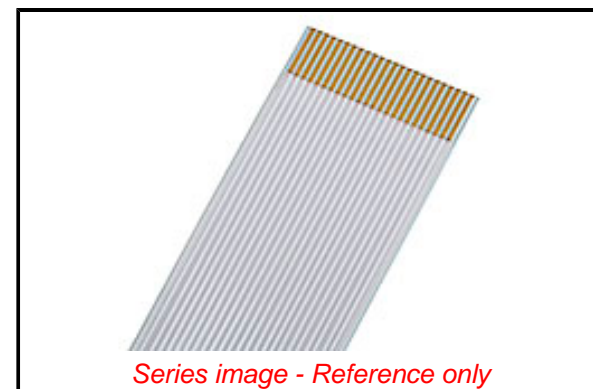

General

Product Family	Cable
Series	15020
Comments	Contacts on the same side, Type A
Crimp Quality Equipment	Yes
Overview	Premo-Flex Flat-Flexible Cable (FFC) Jumpers
Product Name	Premo-Flex FFC Jumper
UPC	884982175594

Physical

Cable Length	51.00mm
Circuits (Loaded)	10
Contact Layout Type	A (same side)
Material - Plating Mating	Gold
Net Weight	0.179/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

Solder Process Data

Lead-free Process Capability	N/A
------------------------------	-----

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-15020-001-001
Product Specification	PS-15020-001-001
Sales Drawing	SD-15020-001

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Contained Per
-ED/01/2018 (15
January 2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

15020 Series

Mates With

Easy-On FFC/FPC Connector:

[5034801000](#) , [5051101092](#) , [527451097](#) ,
[527461071](#) , [5019511030](#) , [5019511050](#) ,
[525591052](#)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15020-0097](#)