

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0150200140](#)
Status: **Active**
Overview: [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)
Description: 0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 30.00mm Cable Length, Gold (Au) Plating, 14 Circuits

Documents:

Drawing (PDF)	Datasheet (PDF)
Product Specification PS-15020-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Cable
Series	15020
Comments	Contacts on opposite sides, Type D
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
UPC	884982176027

Physical

Cable Length	30.00mm
Circuits (Loaded)	14
Contact Layout Type	D (opposite side)
Material - Plating Mating	Gold
Net Weight	0.156/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable


Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

Material Info

Reference - Drawing Numbers

Product Specification	PS-15020-001-001
Sales Drawing	SD-15020-001-001

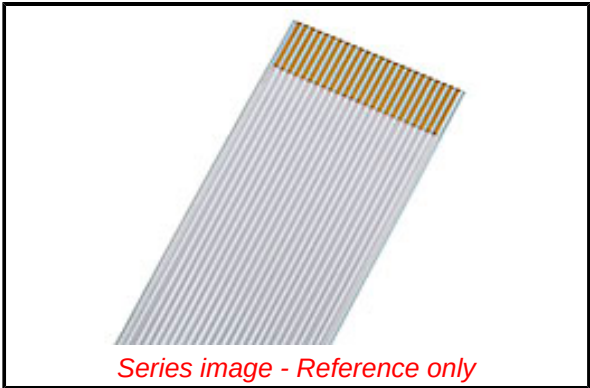

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China RoHS

China ROHS	Not Reviewed
ELV	Not Relevant
RoHS Phthalates	Not Reviewed

Search Parts in this Series

[15020](#) Series

Mates With

Easy-On FFC/FPC Connector:

[5034801400](#) , [5051101492](#) , [527451497](#) ,
[527461471](#) , [5019511430](#) , [5019511450](#) ,
[525591452](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15020-0140](#)