


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0150200261](#)
Status: **Active**
Overview: [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)
Description: 0.50mm Pitch Premo-Flex FFC Jumper, Same Side Contacts (Type A), 178.00mm Cable Length, Gold (Au) Plating, 24 Circuits

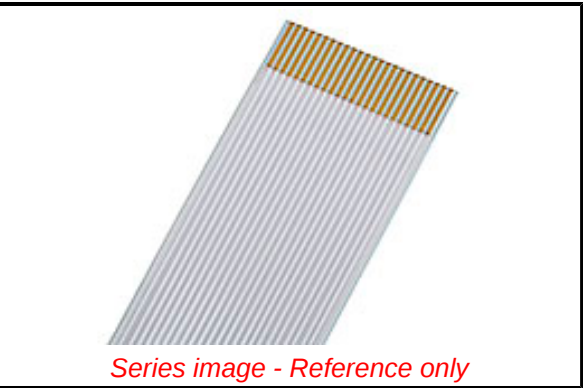

Series image - Reference only

Documents:

Drawing (PDF)	Datasheet (PDF)
Product Specification PS-15020-001-001 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	Cable
Series	15020
Comments	Contacts on the same side, Type A
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex FFC Jumper
UPC	884982177239

Physical

Cable Length	178.00mm
Circuits (Loaded)	24
Contact Layout Type	A (same side)
Material - Plating Mating	Gold
Net Weight	1.383/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Flex Cable

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	60V AC

Material Info

Reference - Drawing Numbers

Product Specification	PS-15020-001-001
Sales Drawing	SD-15020-001-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[15020 Series](#)

Mates With

Easy-On FFC/FPC Connector:

[5034802400](#) , [5051102491](#) , [524352471](#) ,
[524372471](#) , [5019512410](#) , [5019512430](#) ,
[5019512450](#) , [525592452](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15020-0261](#)