


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

**Part Number:** [0150200356](#)  
**Status:** **Active**  
**Overview:** [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)  
**Description:** 0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 254.00mm Cable Length, Gold (Au) Plating, 32 Circuits

**Documents:**  
[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)  
[Product Specification PS-15020-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

|                                    |                                                                           |
|------------------------------------|---------------------------------------------------------------------------|
| <b>General</b>                     |                                                                           |
| Product Family                     | Cable                                                                     |
| Series                             | <a href="#">15020</a>                                                     |
| Comments                           | Contacts on opposite sides, Type D                                        |
| Crimp Quality Equipment            | Yes                                                                       |
| Overview                           | <a href="#">FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers</a> |
| Product Name                       | Premo-Flex FFC Jumper                                                     |
| UPC                                | 884982178182                                                              |
| <b>Physical</b>                    |                                                                           |
| Cable Length                       | 254.00mm                                                                  |
| Circuits (Loaded)                  | 32                                                                        |
| Contact Layout Type                | D (opposite side)                                                         |
| Material - Plating Mating          | Gold                                                                      |
| Net Weight                         | 2.605/g                                                                   |
| Packaging Type                     | Bag                                                                       |
| Pitch - Mating Interface           | 0.50mm                                                                    |
| Temperature Range - Operating      | -40° to +105°C                                                            |
| Wire Size AWG                      | N/A                                                                       |
| Wire/Cable Type                    | Flat Flex Cable                                                           |
| <b>Electrical</b>                  |                                                                           |
| Current - Maximum per Contact      | 0.5A                                                                      |
| Voltage - Maximum                  | 60V AC                                                                    |
| <b>Material Info</b>               |                                                                           |
| <b>Reference - Drawing Numbers</b> |                                                                           |
| Product Specification              | PS-15020-001-001                                                          |
| Sales Drawing                      | SD-15020-001-001                                                          |

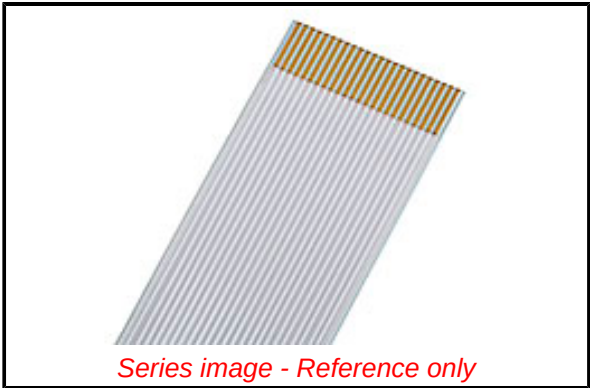

|                                                                                                                                           |                   |
|-------------------------------------------------------------------------------------------------------------------------------------------|-------------------|
| <b>EU ELV</b><br><b>Not Reviewed</b>                                                                                                      |                   |
| <b>EU RoHS</b><br><b>Not Reviewed</b><br><b>REACH SVHC</b><br>Not Reviewed<br><b>Halogen-Free</b><br><b>Status</b><br><b>Not Reviewed</b> | <b>China RoHS</b> |
| For more information, please visit <a href="#">Contact US</a>                                                                             |                   |
| China ROHS                                                                                                                                | Not Reviewed      |
| ELV                                                                                                                                       | Not Reviewed      |
| RoHS Phthalates                                                                                                                           | Not Reviewed      |

**Search Parts in this Series**  
[15020](#) Series

**Mates With**  
Easy-On FFC/FPC Connector: <br>  
[5034803200](#) , [5051103291](#) , [5051103296](#)  
 , [541043231](#) , [541323262](#) , [5019513210](#) ,  
[5019513230](#) , [5019513250](#) , [525593252](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15020-0356](#)