

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0150200748

Status: Active

Overview: FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers

Description: 0.50mm Pitch Premo-Flex FFC Jumper, Opposite Side Contacts (Type D), 76.00mm Cable Length, Gold (Au) Plating, 7 Circuits

Documents:

[Drawing \(PDF\)](#) [Datasheet \(PDF\)](#)
[Product Specification PS-15020-001-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family Cable
Series 15020
Comments Contacts on the same side, Type A
Crimp Quality Equipment Yes
Overview FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name Premo-Flex FFC Jumper
UPC 884982180239

Physical

Cable Length 76.00mm
Circuits (Loaded) 7
Contact Layout Type A (same side)
Material - Plating Mating Gold
Packaging Type Bag
Pitch - Mating Interface 0.50mm
Temperature Range - Operating -40° to +105°C
Wire Size AWG N/A
Wire/Cable Type Flat Flex Cable


Electrical

Current - Maximum per Contact 0.5A
Voltage - Maximum 60V AC

Material Info

Reference - Drawing Numbers

Product Specification PS-15020-001-001
Sales Drawing SD-15020-001-001

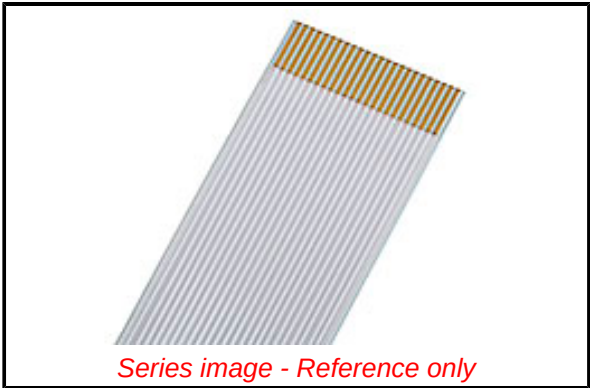

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

15020 Series

Mates With

Easy-On FFC/FPC Connector:

[5051100792](#) , [527450797](#) , [527460771](#) ,
[5019510730](#) , [5019510750](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15020-0748](#)