

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0150222480](#)
Status: **Active**
Overview: [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)
Description: 0.50mm Pitch Premo-Flex LVDS Jumper, 610.00mm Cable Length, Gold (Au) Plating, 80 Circuits

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Datasheet \(PDF\)](#)

General

Product Family Cable
Series [15022](#)
Crimp Quality Equipment Yes
Overview [FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers](#)
Product Name Premo-Flex LVDS Jumper
UPC 889056697521

Physical


Cable Length 610.00mm
Circuits (Loaded) 80
Contact Layout Type A (same side)
Material - Outer Jacket Polyester
Material - Plating Mating Gold
Packaging Type Bag
Pitch - Mating Interface 0.50mm
Temperature Range - Operating -40° to +80°C
Wire Size AWG N/A
Wire/Cable Type Flat Cable

Electrical

Current - Maximum per Contact 0.5A
Voltage - Maximum 30V AC

Material Info

Reference - Drawing Numbers
Sales Drawing SD-15022-080-001

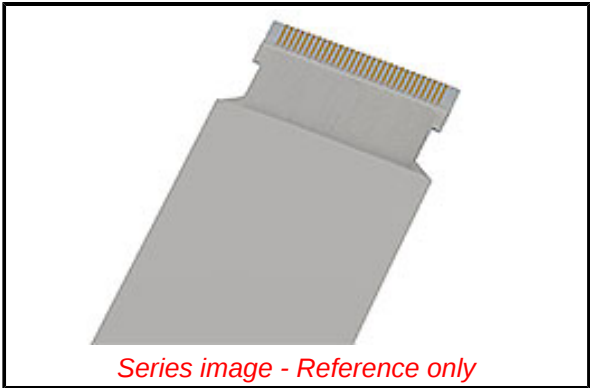

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[15022 Series](#)

Mates With

Easy-On FFC/FPC Connector [5017868090](#) ,
[5018648090](#)

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

15022-2480