

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0151310206

Status:


Active

Overview:

Pico-Lock Connector System

Description:

Pico-Lock-to-Pico-Lock Off-the-Shelf (OTS) Cable Assembly, 1.00mm Pitch, Single Row, 600.00mm Length, 2 Circuits, Black

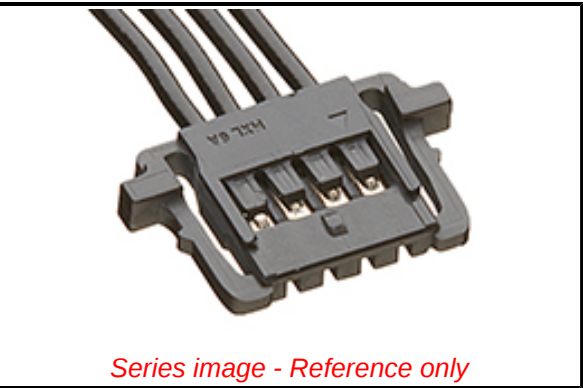

Documents:

3D Model

Drawing (PDF)

3D Model (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable Assemblies
Series	15131
Application	Signal, Wire-to-Board
Assembly Configuration	Dual Ended Connectors
Connector to Connector	Pico-Lock-to-Pico-Lock
Overmolded	No
Overview	Pico-Lock Connector System
Product Name	Pico-Lock
Type	Discrete Wire Assembly
UPC	191128284745
Physical	
Cable Length	600.00mm
Circuits (Loaded)	2
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Material - Resin	High Temperature Thermoplastic
Net Weight	2.003/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	1.00mm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.60mm
Wire Size AWG	28
Wire/Cable Type	UL 1571
Electrical	
Current - Maximum per Contact	2.5A
Voltage - Maximum	150V
Material Info	
Reference - Drawing Numbers	
Sales Drawing	151310200-000

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per - D(2021)4569-DC (8 July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

15131 Series

Mates With

Pico-Lock Header 503763

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15131-0206](#)