

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0151340205**  
**Status:** **Active**  
**Overview:** PicoBlade Connector System  
**Description:** PicoBlade Female-to-PicoBlade Female Off-the-Shelf (OTS) Cable Assembly, Single Row, 450.00mm Length, 2 Circuits, Natural

**Documents:**

[3D Model](#) [Datasheet \(PDF\)](#)  
[3D Model \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Drawing \(PDF\)](#)

**General**

Product Family	Cable Assemblies
Series	<u>15134</u>
Application	Signal, Wire-to-Board, Wire-to-Wire
Assembly Configuration	Dual Ended Connectors
Connector to Connector	PicoBlade-to-PicoBlade
Overmolded	No
Overview	<u>PicoBlade Connector System</u>
Product Name	PicoBlade
Type	Discrete Wire Assembly
UPC	889056870733

**Physical**

Cable Length	450.00mm
Circuits (Loaded)	2
Color - Resin	Natural
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	1.794/g
Number of Rows	1
Packaging Type	Bag
Pitch - Mating Interface	1.25mm
Plating min - Mating	0.889µm
Plating min - Termination	0.914µm
Single Ended	No
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.90mm
Wire Size AWG	28
Wire/Cable Type	UL 1061


**Electrical**

Current - Maximum per Contact	1.0A
Voltage - Maximum	125V

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing	2012341354-000
---------------	----------------

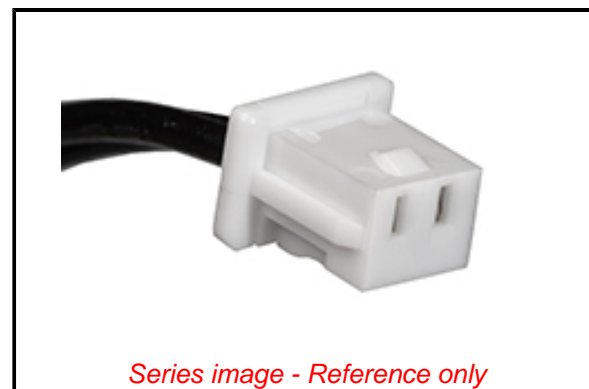

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
D(2021)4569-DC (8  
July 2021)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[15134 Series](#)

**Mates With**

PicoBlade Header [53261](#) , [53047](#) , [53398](#) ,  
[53048](#) . PicoBlade Plug Housing [51047](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[15134-0205](#)