

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190030053

Status:

Active

Overview:

Standard Quick-Disconnect Terminals

Description:

InsulKrimp Female Quick Disconnect, for 14-16 AWG Wire

Documents:

3D Model

Product Specification PS-19902-011-001 (PDF)

3D Model (PDF)

Product Specification PS-19902-013-001 (PDF)

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Product Specification PS-19902-008-001 (PDF)

Agency Certification

CSA

LR18689

UL

E79133

General

Product Family

Quick Disconnects

Series

19003

Comments

Funnel Entry

Crimp Quality Equipment

Yes

Insulated

Fully

Overview

Standard Quick-Disconnect Terminals

Product Name

InsulKrimp

Type

Quick Disconnect

UPC

800753029323

Physical

Barrel Type

Closed

Color - Resin

Blue

Flammability

94V-2

Gender

Female

Glow-Wire Capable

No

Insulation

Nylon (PA)

Lock to Mating Part

None

Material - Metal

Brass

Material - Plating Mating

Tin

Material - Plating Termination

Tin

Material - Resin

Nylon

Net Weight

0.865/g

Orientation

Straight

Packaging Type

Bag

Plating min - Mating

4.064µm

Plating min - Termination

4.064µm

Polarized to Mating Part

No

Tab Thickness

0.51mm

Tab Width

4.75mm

Temperature Range - Operating

-65° to +105°C

Termination Interface: Style

Crimp or Compression

Wire Insulation Diameter

6.60mm max.

Wire Size AWG

14, 16

Wire Size mm²

1.30-2.00

Electrical


Voltage - Maximum

600V

Solder Process Data

Lead-freeProcess Capability

N/A

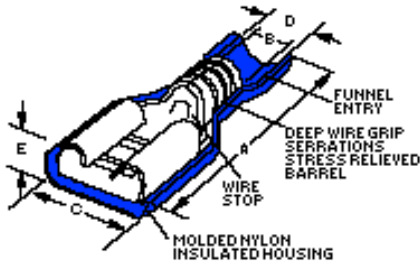

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

19003 Series

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade	640010400
Hand Crimp Tool for InsulKrimp Quick Disconnect Terminals, 10-22 AWG	
Crimp Head for the AT-200 Pneumatic Hand Tool	640050400

Material Info

Engineering Number BB-2207X

Reference - Drawing Numbers

Product Specification PS-19902-008-001, PS-19902-011-001,
PS-19902-013-001
Sales Drawing SD-19003-006-001

This document was generated on 09/13/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19003-0053](#)