

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190050008](#)
Status: **Active**
Overview: [Standard Quick-Disconnect Terminals](#)
Description: InsulKrimp Fully Insulated Coupler, Female, for 14-16 AWG Wire, Continuous Molded Strip

Documents:
[3D Model](#) [Product Specification PS-19902-008-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [Product Specification PS-19902-011-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR18689
UL E79133


General
Product Family Quick Disconnects
Series [19005](#)
Crimp Quality Equipment Yes
Insulated Fully
Overview [Standard Quick-Disconnect Terminals](#)
Product Name InsulKrimp
Type Quick Disconnect
UPC 800753030534

Physical
Barrel Type Closed
Color - Resin Blue
Flammability 94V-2
Gender Female
Glow-Wire Capable No
Insulation Nylon (PA)
Lock to Mating Part None
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Material - Resin Nylon
Net Weight 1.359/g
Orientation Straight
Packaging Type Reel
Polarized to Mating Part No
Tab Thickness 0.81mm
Tab Width 6.35mm
Temperature Range - Operating -65° to +105°C
Wire Insulation Diameter 4.19mm max.
Wire Size AWG 14, 16
Wire Size mm² 1.30-2.00

Electrical
Voltage - Maximum 600V

Material Info
Engineering Number BB-2263C

Reference - Drawing Numbers
Product Specification PS-19902-008-001, PS-19902-011-001
Sales Drawing SD-19005-001-001

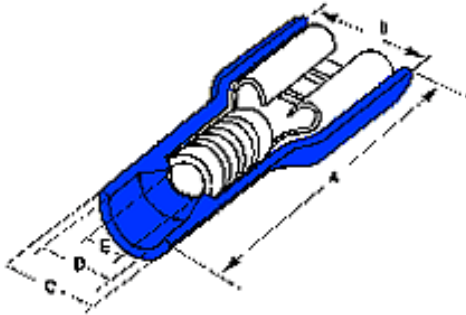

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per -
D(2021)4569-DC (8
July 2021)
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
[19005 Series](#)

Use With
[190040005](#) , [190040008](#)

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
Mini-Mac Applicator	638832600

This document was generated on 09/22/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19005-0008](#)