

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190070076

Status:

Active

Overview:

Standard Quick-Disconnect Terminals

Description:

InsulKrimp Female Fully Insulated Quick Disconnect Flag for 16-14 AWG Wire, Tab 4.75 x 0.51mm, 94 V-0 Material

Documents:

- [Drawing \(PDF\)](#)
- [Product Specification PS-19902-008-001 \(PDF\)](#)
- [Product Specification PS-19902-011-001 \(PDF\)](#)
- [Product Specification PS-19902-013-001 \(PDF\)](#)
- [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL

E79133

General

Product Family

Series

Crimp Quality Equipment

Insulated

Overview

Product Name

Type

UPC

Quick Disconnects

19007

Yes

Fully

Standard Quick-Disconnect Terminals

InsulKrimp

Quick Disconnect

800756384825

Physical

Barrel Type

Color - Resin

Flammability

Gender

Glow-Wire Capable

Insulation

Lock to Mating Part

Material - Metal

Material - Plating Mating

Material - Plating Termination

Material - Resin

Net Weight

Orientation

Packaging Type

Polarized to Mating Part

Tab Thickness

Tab Width

Temperature Range - Operating

Wire Insulation Diameter

Wire Size AWG

Closed

Blue

94V-0

Female

Yes

Nylon (PA)

None

Brass

Tin

Tin

Nylon

1.390/g

Flag

Bag

No

0.51mm

4.75mm

-65° to +105°C

5.08mm

14, 16

Electrical

Voltage - Maximum

600V

Material Info

Engineering Number

BB-2224V


Reference - Drawing Numbers

Product Specification

Sales Drawing

PS-19902-008-001, PS-19902-011-001, PS-19902-013-001

SD-19007-001-001

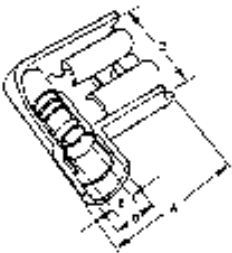

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Contained Per -
D(2021)4569-DC (8 July 2021)
1,2-Benzenedicarboxylic acid, bis(3-methylbutyl) 1,2-diethoxyethane Dibutyltin-dichloride 1,3-Propanesultone C.I. Direct Black 38 Disodium-octaborate 2-ethylhexyl 10-ethyl-4,4-dioctyl-7-oxo-8-oxa-3,2-(2H-Benzotriazol-2-yl)-4,6-ditertpentylphenol 2-(2H-Benzotriazol-2-yl)-4-(tert-butyl)-6-(sec-b Terphenyl, hydrogenated 1,2-Benzenedicarboxylic acid, dihexyl ester, bra diisohexyl phthalate 1,2-Benzenedicarboxylic acid, dipentyl ester, br n-pentyl-isopentylphthalate Boric acid Aluminosilicate Refractory Ceramic Fibres Zirconia Aluminosilicate

China RoHS

Refractory Ceramic
Fibr
Tris(4-nonylphenyl,
branched and linear)
phosphi
Pyrene
Diocetyl tin dilaurate,
stannane, dioctyl-,
bis(co
Perfluorononan-1-
oic acid
(2,2,3,3,4,4,5,5,6,6,7
reaction mass of
2-ethylhexyl 10-
ethyl-4,4-dioct
Perfluorohexane-1-
sulphonic acid and its
salts
Strontium-chromate
1,2-
Benzenedicarboxylic
acid, di-C7-11-
branched
Diboron-trioxide
Cadmium-oxide
Cadmium-sulphide
Lead(II,IV)-oxide
Pentalead-tetraoxide-
sulphate
Trilead-dioxide-
phosphonate
Cyanamide, lead(2+)
salt (1:1)
Cadmium Hydroxide
Sulfurous Acid, Lead
Salt, Dibasic
4-aminoazobenzene
Dicyclohexyl-
phthalate
Dihexyl-phthalate
Phenanthrene
Imidazolidine-2-thione
Dipentyl phthalate
Benzo(ghi)perylene
Octanoic acid,
2,2,3,3,4,4,5,5,6,6,7,7,8,8,8-
pen
Dodecamethylcyclhexasiloxane
Decamethylcyclopentasiloxane
Octamethylcyclotetrasiloxane
Disodium 3,3'-[[1,1'-
Biphenyl]-4,4'-
Diylbis(Azo)

**Halogen-Free
Status**

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19007](#) Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade Hand Crimp Tool for Flag Insulkrimp Quick Disconnect Terminals, 14-22AWG	<u>640014100</u>
Crimp Head for the AT-200 Pneumatic Hand Tool	<u>640054100</u>

This document was generated on 09/13/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19007-0076](#)