

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190160004](#)
Status: **Active**
Overview: [Standard Quick-Disconnect Terminals](#)
Description: Krimptite Quick Disconnect, Female, for 18-22 (0.80-0.35mm²) Wire, Mylar Tape, Tab 2.79 x 0.81mm

Documents:
[3D Model](#) [Product Specification PS-19902-011-001 \(PDF\)](#)
[3D Model \(PDF\)](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-005-001 \(PDF\)](#)

Agency Certification
CSA LR18689
UL E79133


General
Product Family Quick Disconnects
Series [19016](#)
Comments Butted Seam
Crimp Quality Equipment Yes
Insulated No
Overview [Standard Quick-Disconnect Terminals](#)
Product Name Krimptite
Type Quick Disconnect
UPC 800753034396

Physical
Barrel Type Closed
Gender Female
Glow-Wire Capable No
Insulation None
Lock to Mating Part None
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.539/g
Orientation Straight
Packaging Type Adhesive Tape on Reel
Polarized to Mating Part No
Tab Thickness 0.81mm
Tab Width 2.79mm
Temperature Range - Operating Per Wire Specification
Termination Interface: Style Crimp or Compression
Wire Size AWG 18, 20, 22

Electrical
Voltage - Maximum Per Wire Specification

Material Info
Engineering Number AA-1134T

Reference - Drawing Numbers
Product Specification PS-19902-005-001, PS-19902-011-001,
PS-19902-015-001
Sales Drawing SD-19016-012-001

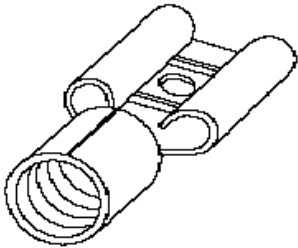

Series image - Reference only

EU ELV
Not Relevant

EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[19016](#) Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	190270037
Mini-Mac Air Feed Mylar Tape Conductor Only Applicator	638858800

This document was generated on 10/04/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19016-0004](#)