

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

**Part Number:** [0190220017](#)  
**Status:** **Active**  
**Overview:** [Standard Quick-Disconnect Terminals](#)  
**Description:** Krimptite Quick Disconnect, Male, for 10-12 (5.00-3.30mm<sup>2</sup>) Wire, Mylar Tape, Tab 6.35 x 0.81mm

**Documents:**  
[3D Model](#)  
[3D Model \(PDF\)](#)  
[Drawing \(PDF\)](#)  
[Product Specification PS-19902-005-001 \(PDF\)](#)  
[Product Specification PS-19902-011-001 \(PDF\)](#)  
[Product Specification PS-19902-015-001 \(PDF\)](#)  
[RoHS Certificate of Compliance \(PDF\)](#)

**General**  
Product Family Quick Disconnects  
Series [19022](#)  
Comments Economical  
Crimp Quality Equipment Yes  
Insulated No  
Overview [Standard Quick-Disconnect Terminals](#)  
Product Name Krimptite  
Type Quick Disconnect  
UPC 800753039575


**Physical**  
Barrel Type Closed  
Gender Male  
Glow-Wire Capable No  
Insulation None  
Lock to Mating Part None  
Material - Metal Brass  
Material - Plating Mating Zinc Chromate  
Material - Plating Termination Zinc Chromate  
Net Weight 1.196/g  
Orientation Straight  
Packaging Type Adhesive Tape on Reel  
Polarized to Mating Part No  
Tab Thickness 0.81mm  
Tab Width 6.35mm  
Temperature Range - Operating Per Wire Specification  
Wire Size AWG 10, 12

**Electrical**  
Voltage - Maximum Per Wire Specification

**Solder Process Data**  
Lead-freeProcess Capability N/A

**Material Info**  
Engineering Number CMCT-1T

**Reference - Drawing Numbers**  
Product Specification PS-19902-005-001, PS-19902-011-001, PS-19902-015-001  
Sales Drawing SD-19022-012-001

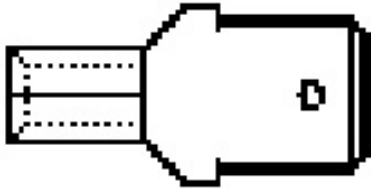

Series image - Reference only

**EU ELV**  
**Not Relevant**

| <b>EU RoHS</b>                                                | <b>China RoHS</b> |
|---------------------------------------------------------------|-------------------|
| <b>Compliant</b>                                              |                   |
| <b>REACH SVHC</b>                                             |                   |
| Not Contained Per - D(2021)4569-DC (8 July 2021)              |                   |
| <b>Halogen-Free</b>                                           |                   |
| <b>Status</b>                                                 |                   |
| <b>Low-Halogen</b>                                            |                   |
| For more information, please visit <a href="#">Contact US</a> |                   |
| China ROHS                                                    | Green Image       |
| ELV                                                           | Not Relevant      |
| RoHS Phthalates                                               | Not Contained     |

**Search Parts in this Series**  
[19022](#) Series

**Application Tooling | [FAQ](#)**  
*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*  
**Global**

| <b>Description</b>                                               | <b>Product #</b>          |
|------------------------------------------------------------------|---------------------------|
| ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press | <a href="#">192880098</a> |

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19022-0017](#)