

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190270300

Status:


Active

Overview:

Application Tooling

Description:

ATP Perishable Tool Kit used in ATP Presses that Process Product on Tape

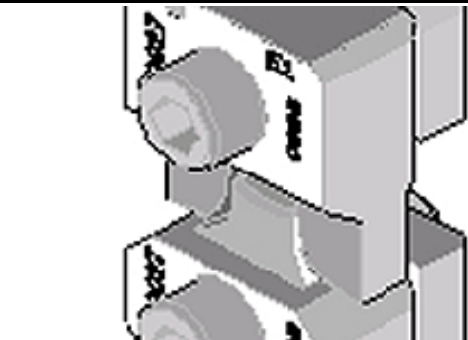

Series image - Reference only

Documents:

RoHS Certificate of Compliance (PDF)

General	
Product Family	Application Tooling
Series	207125
Function	Crimp
Geographic Area	Global
Level of Automation	Semi-Automatic
More Detailed Tech Information	applicationtooling@molex.com
Overview	Application Tooling
Product Name	N/A
Tool Type	Pneumatic Press
UPC	756054850725
Warranty Disclaimer	CAUTION: Molex tooling crimp specifications are valid only when used with Molex terminals and tooling manufactured by Molex and sold by Molex or authorized distributors ("Molex Tooling"). When using tooling other than Molex Tooling with Molex specific connector systems listed in our ATS documents, the Molex tooling qualification does not apply and the responsibility for full qualification of the connector system is that of the customer. Molex accepts no liability for connector performance or tooling support where tooling other than Molex Tooling is used or where Molex Tooling is modified.

Material Info	
Engineering Number	ATP

Reference - Drawing Numbers	
Application Tooling Documents	ATS-190270300-001, TM-192280498-001, TM-640160065-001, TM-640160065CN-001, TM-640160065DE-001, TM-640160065FR-001, TM-640160065IT-001, TM-640160065JP-001, TM-640160065KR-001, TM-640160065MY-001, TM-640160065PL-001, TM-640160065RU-001, TM-640160065SK-001, TM-640160065SP-001, TM-640160065TH-001, TM-640160065TW-001, TM-640160065VN-001

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS	Not Reviewed
ELV	Not Reviewed
RoHS Phthalates	Not Reviewed

Search Parts in this Series

207125 Series

Use With

ATP-301 press, ATP-101 press, ATP-101W press, ATP-101WDI, ATP-101HD

Application Tooling Description	FAQ Product #
Krimptite Ring	190440185
Tongue Terminal for 14-16 Heavy Duty AWG Wire	
Krimptite Ring	190690240
Tongue Terminal for 10-12 AWG Wire, Stud Size 1/4" (M6), Length 26.82mm, Mylar Tape Carrier	
Krimptite Ring	190690243
Tongue Terminal for 10-12 AWG Wire, Stud Size 3/8" (M9), Length 26.82mm, Mylar Tape Carrier	
Krimptite Ring	190690246
Tongue Terminal for	

10-12 AWG Wire,
Stud Size 5/16" (M8),
Length 26.82mm,
Mylar Tape Carrier

This document was generated on 07/31/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19027-0300