

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190340007](#)
Status: **Active**
Overview: [Snap Plugs and Receptacles](#)
Description: InsulKrimp Snap Plug, for 14-16 AWG Wire, 24.13mm Length

Documents:	
3D Model	Product Specification PS-19902-011-001 (PDF)
3D Model (PDF)	Product Specification PS-19902-013-001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR18689
UL	E152602

General

Product Family	Quick Disconnects
Series	19034
Crimp Quality Equipment	Yes
Insulated	Partial
Overview	Snap Plugs and Receptacles
Product Name	InsulKrimp
Type	Snap Plug
UPC	800753047365

Physical

Barrel Type	Closed
Color - Resin	Blue
Flammability	94V-0
Gender	Male
Glow-Wire Capable	No
Insulation	PVC
Lock to Mating Part	None
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	PVC
Net Weight	1.579/g
Orientation	Straight
Packaging Type	Bag
Tab Thickness	N/A
Tab Width	N/A
Wire Insulation Diameter	4.40mm max.
Wire Size AWG	14, 16
Wire Size mm²	1.30-2.00

Electrical


Voltage - Maximum	600V
-------------------	------

Material Info

Engineering Number	B-279X
--------------------	--------

Reference - Drawing Numbers

Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19034-004-001

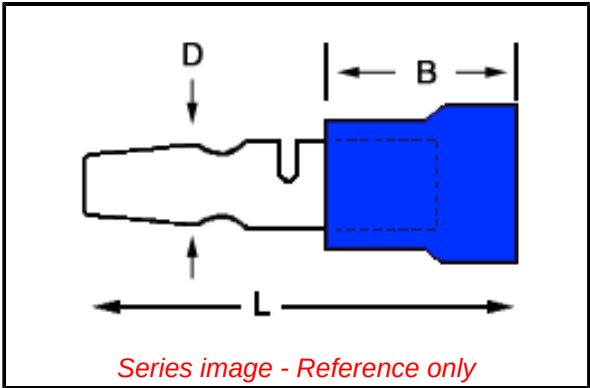

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

[19034](#) Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm² (Rings, Spades, Hooks, Block Spades and Flanged Spades)	640010100
PremiumGrade Hand Crimp Tool for Insulkrimp Terminals and Splices, 10-22	640010300

AWG (Rings,
Spades, Hooks,
Block Spades and
Flanged Spades)
Crimp Head for the 640050100
AT-200 Pneumatic
Hand Tool
Crimp Head for the 640050300
AT-200 Pneumatic
Hand Tool
ServiceGrade Hand 640160036
Crimp Tool for Field
Repair only, for
production use our
PremiumGrade Tool

This document was generated on 09/13/2021
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19034-0007](#)