

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0190410012](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: Krimptite Ring Tongue Terminal Flag for 14-16 AWG Wire, Stud Size 10 (M5)

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


General
Product Family Ring and Spade Terminals
Series [19041](#)
Crimp Quality Equipment Yes
Overview [Solderless Terminals](#)
Product Name Krimptite
Type Ring
UPC 800755059267

Physical
Barrel Type Closed
Insulation None
Material - Plating Mating Tin
Net Weight 1.012/g
Packaging Type Bag
Stud Size 10 (M5)
Wire Size AWG 14, 16
Wire Size mm² 1.00-2.50

Solder Process Data
Lead-freeProcess Capability N/A

Material Info
Engineering Number B-143-10

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing BCD10701

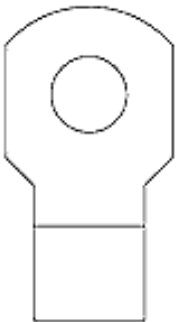

Series image - Reference only

EU ELV
Not Relevant

EU RoHS Compliant REACH SVHC Not Contained Per - ED/71/2019 (16 July 2019) Halogen-Free Status Low-Halogen For more information, please visit Contact US	China RoHS China ROHS Green Image ELV Not Relevant RoHS Phthalates Not Contained
---	--

Search Parts in this Series
[19041 Series](#)

Application Tooling | [FAQ](#)
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.
Global

Description	Product #
Hand Crimp Tool	640030800
Crimp Head for the AT-200 Pneumatic Hand Tool	640070800

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19041-0012](#)