


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

**Part Number:** [0190440154](#)  
**Status:** **Active**  
**Description:** RING KRIMPTITE (B-123-08) SPM

|                                |                                                              |
|--------------------------------|--------------------------------------------------------------|
| <b>Documents:</b>              |                                                              |
| <a href="#">3D Model</a>       | <a href="#">Product Specification PS-19902-011-001 (PDF)</a> |
| <a href="#">3D Model (PDF)</a> | <a href="#">Product Specification PS-19902-013-001 (PDF)</a> |
| <a href="#">Drawing (PDF)</a>  | <a href="#">RoHS Certificate of Compliance (PDF)</a>         |

|                                    |                                    |
|------------------------------------|------------------------------------|
| <b>Agency Certification</b>        |                                    |
| CSA                                | LR18689                            |
| UL                                 | E32244                             |
| <b>General</b>                     |                                    |
| Product Family                     | Ring and Spade Terminals           |
| Series                             | <a href="#">19044</a>              |
| Crimp Quality Equipment            | Yes                                |
| UPC                                | 800755060263                       |
| <b>Physical</b>                    |                                    |
| Net Weight                         | 0.617/g                            |
| Plating min: Mating (µin)          | 160                                |
| Plating min: Mating (µm)           | 4                                  |
| Plating min: Termination (µin)     | 160                                |
| Plating min: Termination (µm)      | 4                                  |
| <b>Material Info</b>               |                                    |
| Engineering Number                 | B-123-08                           |
| <b>Reference - Drawing Numbers</b> |                                    |
| Product Specification              | PS-19902-011-001, PS-19902-013-001 |
| Sales Drawing                      | 190440143-000                      |

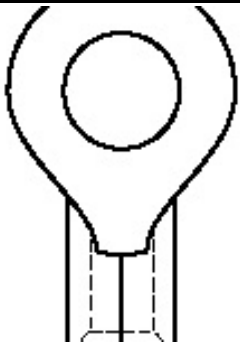

Series image - Reference only

|                                                                             |                   |
|-----------------------------------------------------------------------------|-------------------|
| <b>EU ELV</b><br><b>Not Relevant</b>                                        |                   |
| <b>EU RoHS</b><br><b>Compliant</b>                                          | <b>China RoHS</b> |
| <b>REACH SVHC</b><br>Not Contained Per -<br>D(2021)4569-DC (8<br>July 2021) |                   |
| <b>Halogen-Free</b><br><b>Status</b><br><b>Low-Halogen</b>                  |                   |
| For more information, please visit <a href="#">Contact US</a>               |                   |
| China ROHS                                                                  | Green Image       |
| ELV                                                                         | Not Relevant      |
| RoHS Phthalates                                                             | Not Contained     |

**Search Parts in this Series**  
[19044](#) Series

**Application Tooling | FAQ**  
*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

|                                                                                               |                           |
|-----------------------------------------------------------------------------------------------|---------------------------|
| <b>Global</b>                                                                                 |                           |
| <b>Description</b>                                                                            | <b>Product #</b>          |
| PremiumGrade                                                                                  | <a href="#">640030100</a> |
| Hand Crimp Tool for Krimptite/Versakrimp Terminals and Splices, 10-22 AWG and 6.0mm² - 0.5mm² |                           |
| Crimp Head for the AT-200 Pneumatic Hand Tool                                                 | <a href="#">640070100</a> |
| ServiceGrade Hand Crimp Tool - Ratchet                                                        | <a href="#">640160038</a> |

This document was generated on 08/31/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19044-0154](#)