

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190440168

Status:


Active

Overview:

High-Temperature Temp Terms Terminals and Splices

Description:

Krimptite Ring Tongue Terminal for 14-16 Heavy Duty AWG Wire

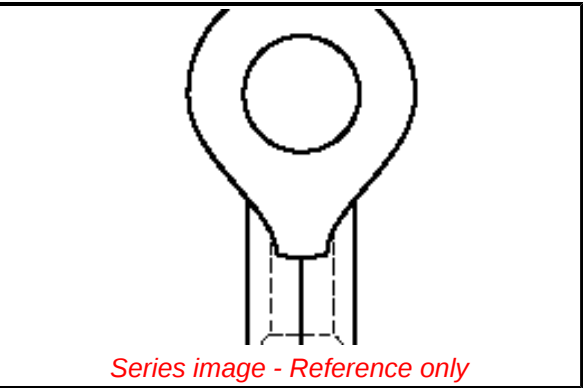

Documents:	
3D Model	Product Specification PS-19902-011-001 (PDF)
Drawing (PDF)	Product Specification PS-19902-013-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19044
Comments	Heavy Duty
Crimp Quality Equipment	Yes
Overview	High-Temperature Temp Terms Terminals and Splices
Product Name	Krimptite
Type	Ring
UPC	800755060348
Physical	
Barrel Type	Closed
Insulation	None
Material - Plating Mating	Tin
Net Weight	2.250/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	5/16" (M8)
Termination Interface: Style	Crimp or Compression
Wire Size AWG	14, 16
Wire Size mm²	1.30-2.00
Material Info	
Engineering Number	B-130-56HD
Reference - Drawing Numbers	
Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19044-008-001

EU ELV Not Relevant	
EU RoHS Compliant	China RoHS
REACH SVHC Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free Status Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19044 Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
PremiumGrade	640030100
Hand Crimp Tool for Krimptite/Versakrimp Terminals and Splices, 10-22 AWG and 6.0mm² - 0.5mm²	
Crimp Head for the AT-200 Pneumatic Hand Tool	640070100
ServiceGrade Hand Crimp Tool - Ratchet	640160038

This document was generated on 09/27/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Molex:](#)

[19044-0168](#)