

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190540113

Status:

Active

Overview:


Solderless Terminals

Description:

InsulKrimp Ring Tongue Terminal for Heavy Duty 14-16 AWG Wire, Vinyl

Documents:	
3D Model	Product Specification PS-19902-011-001 (PDF)
Drawing (PDF)	Product Specification PS-19902-013-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-19902-009-001 (PDF)	

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19054
Comments	Heavy Duty
Crimp Quality Equipment	Yes
Overview	Solderless Terminals
Product Name	InsulKrimp
Type	Ring
UPC	800753054981
Physical	
Barrel Type	Closed
Color - Resin	Blue
Flammability	94V-0
Insulation	PVC
Material - Metal	Copper
Material - Plating Mating	Tin
Net Weight	0.979/g
Packaging Type	Carton
Stud Size	10 (M5)
Temperature Range - Operating	105°C
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	4.45mm max.
Wire Size AWG	14, 16
Wire Size mm²	1.00-2.50
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Engineering Number	B-237-10X
Reference - Drawing Numbers	
Product Specification	PS-19902-009-001, PS-19902-011-001, PS-19902-013-001
Sales Drawing	190540072-000

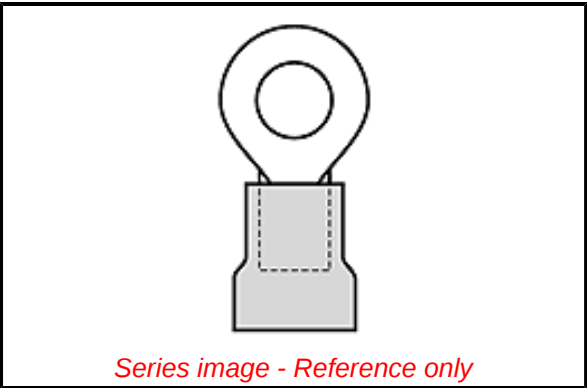

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2021)4569-DC (8 July 2021)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19054 Series

Application Tooling | [FAQ](#)

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Mini-Mac Applicator	638853400
PremiumGrade	640010100
Hand Crimp Tool for Avikrimp and Insulkrimp Terminals and Splices, 10-22 AWG and 6.0-0.5mm² (Rings, Spades, Hooks, Block Spades and Flanged Spades)	
Crimp Head for the AT-200 Pneumatic Hand Tool	640050100

ServiceGrade Hand 640160036
Crimp Tool for Field
Repair only, for
production use our
PremiumGrade Tool
Taped Terminal 640162000
Crimp Module used
with TM-3000 and
TM-4000 presses
with ATP-201 and
ATP-301 die sets.

This document was generated on 09/13/2021
PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19054-0113