

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190670106

Status:

Active

Overview:

Solderless Terminals

Description:

NylaKrimp Funnel Entry Ring Tongue Terminal for 1/0 AWG Wire, Stud Size 3/4" (M18)

Documents:

Drawing (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-013-001 (PDF)

Product Specification PS-19902-016-001 (PDF)


RoHS Certificate of Compliance (PDF)

Agency Certification		
UL		E32244
General		
Product Family		Ring and Spade Terminals
Series		19067
Crimp Quality Equipment		Yes
Overview		Solderless Terminals
Product Name		NylaKrimp
Type		Ring
UPC		800753066939
Physical		
Barrel Type		Closed - Brazed
Flammability		94V-2
Insulation		Nylon (PA)
Material - Plating Mating		Tin
Net Weight		8.404/g
Packaging Type		Bag
Plating min - Mating		2.540µm
Plating min - Termination		2.540µm
Stud Size		3/4" (M18)
Termination Interface: Style		Crimp or Compression
Wire Insulation Diameter		17.27mm max.
Wire Size AWG		1
Material Info		
Engineering Number		H-982-34

Reference - Drawing Numbers

Product Specification

PS-19902-011-001, PS-19902-013-001, PS-19902-016-001

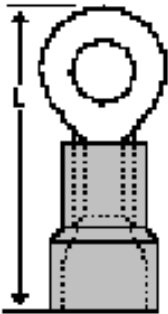

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Not Reviewed	
REACH SVHC	
Not Contained Per - ED/30/2017 (7 July 2017)	
Halogen-Free Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19067 Series

Application Tooling FAQ	
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.	
Global	
Description	Product #
Manual Putt Pump Hydraulic System, Die set required	192860117
Hydraulic Dieless Crimping Tool	638161700

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19067-0106