


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:	<u>0190670109</u>
Status:	Active
Overview:	<u>Solderless Terminals</u>
Description:	NylaKrimp Funnel Entry Ring Tongue Terminal for 2/0 AWG Wire, Stud Size 1/2" (M12)

Documents:

3D Model	Product Specification PS-19902-013-001 (PDF)
Drawing (PDF)	Product Specification PS-19902-016-001 (PDF)
3D Model (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-19902-011-001 (PDF)	

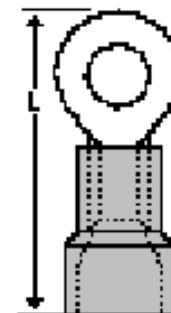

Series image - Reference only

Agency Certification

UL E32244

General

Product Family	Ring and Spade Terminals
Series	<u>19067</u>
Crimp Quality Equipment	Yes
Overview	<u>Solderless Terminals</u>
Product Name	NylaKrimp
Type	Ring
UPC	800753066991

Physical

Barrel Type	Closed - Brazed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	48.770/g
Packaging Type	Bag
Plating min - Mating	2.540μm
Plating min - Termination	2.540μm
Stud Size	1/2" (M12)
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	19.43mm max.
Wire Size AWG	2/0

Material Info

Engineering Number J-985-12

Reference - Drawing Numbers

Product Specification	PS-19902-011-001, PS-19902-013-001, PS-19902-016-001
Sales Drawing	SD-19067-001-001

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)4569-DC (8
July 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19067 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Manual Putt Pump Hydraulic System, Die set required	<u>192860117</u>
Die Set (large) for the HHLS Hydraulic Crimper	<u>192890025</u>
Hydraulic Dieless Crimping Tool	<u>638161700</u>

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Molex:

19067-0109